


## Wall mount



## HEX190PD series

### Dimension drawing

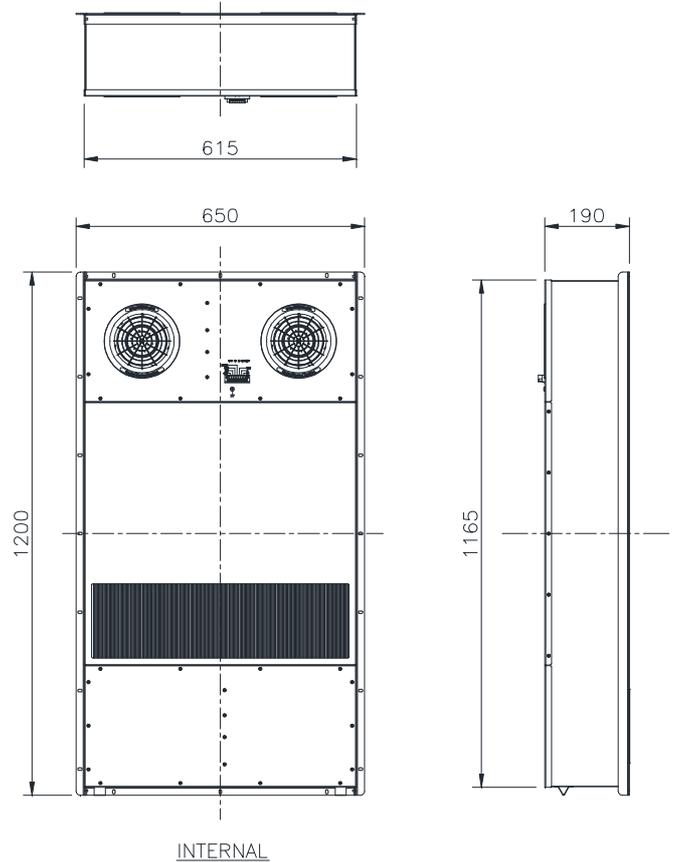

### Features

- ◆ Reliable and energy efficient thermal solutions.
- ◆ IP55 waterproof at external side.
- ◆ Dry contact alarm output.

### Design

- ◆ Compact size.
- ◆ Rated voltage at 48V.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	1200 x 650 x 190 (47.2 x 25.6 x 7.5)
Cooling capacity	W/K	190
Rated voltage	VDC	48
Operating current	A	7.8
Operating Power	W	375
Operating voltage range	VDC	40 - 60
Operating temperature range	℃	-10 - +65
Noise (1.5 meter)	dB-A	65
Weight	Kg (Lb)	40 (88)

\* Specifications are subject to change without notice.