

# Igniter

## IGT003 Type



### Features

- With the aids of this starter, the ballast can provide 16.5 KVo-p typical to start the lamp of projector.

### Applications

- Projector

**Mechanical Dimension:** Unit: mm

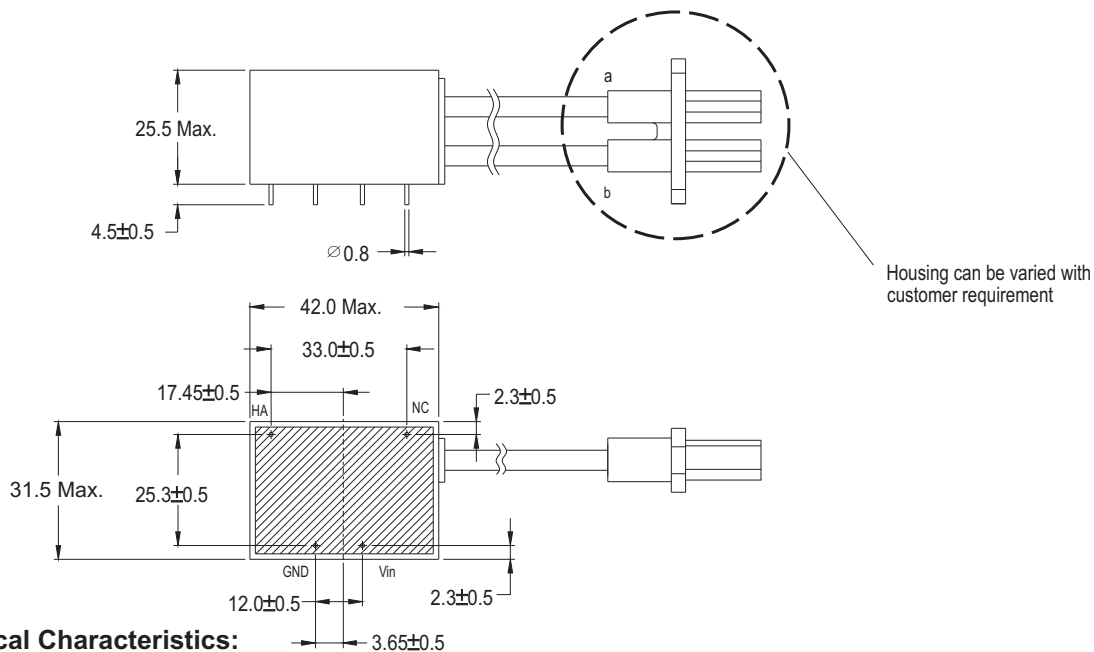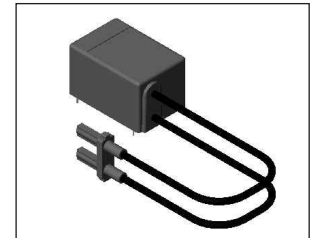


### Electrical Characteristics:

- AT 25°C, 65%RH

PART NO.	INPUT VOLTAGE (Vdc)	HA OUTPUT VOLTAGE (KVo-p)	SWITCHING LIFE (times)	WEIGHT
IGT-003	240 Min.	14.0 Min.	10 <sup>6</sup> Min.	75g

- Switching frequency : 35Hz reference
- Storage temperature: -20C to +70C
- Operating temperature : -10C to + 55C
- Insulated with epoxy resin

### Recommended Circuit:

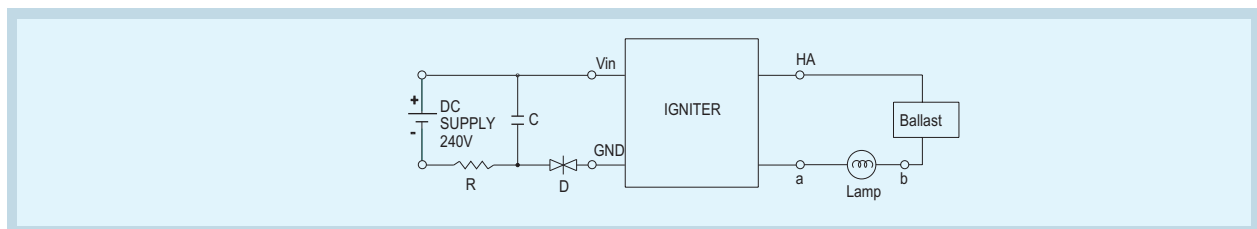

**DELTA ELECTRONICS, INC.**

(TAOYUAN PLANT CPBG) 252, SAN YING ROAD, KUEISAN INDUSTRIAL ZONE, TAOYUAN SHIEN, 333, TAIWAN, R.O.C.

TEL: 886-3-3591968; FAX: 886-3-3591991

<http://www.deltaww.com>