


## Wall / Bottom Mount

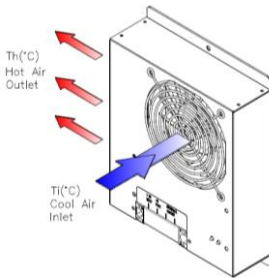

Airflow orientation

### Features


- ◆ Quick heating
- ◆ Constant Air Flow
- ◆ Compact design
- ◆ High efficiency and reliable DC fan
- ◆ Overheat & short protect function
- ◆ Easy for wall mount or bottom mount

## HEH100PA



### Dimension drawing

NOTE :  
 (1) Material : SGCC T=1.0mm  
 (2) Finish : Powder paint 75~120um, Color 7032  
 (3) Dimensional tolerance : ± 1.0mm

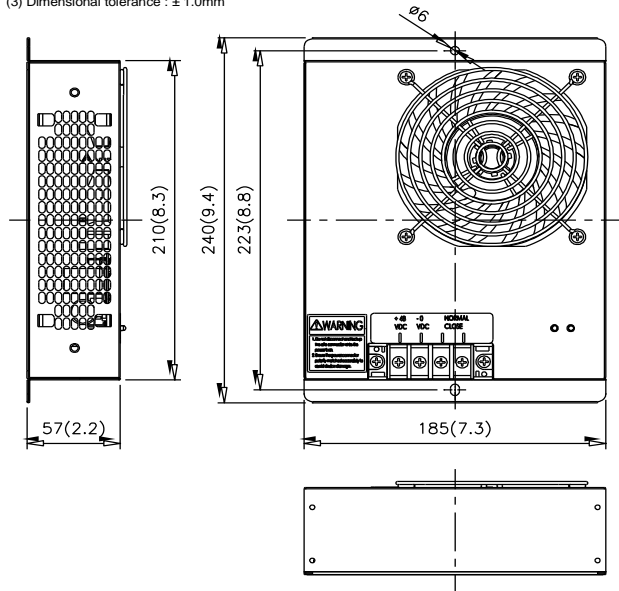

Main feature	Unit	Specification
Outline Dimension	mm (inch)	240H x 185W x 57D (9.4 x 7.3 x 2.2)
Heating Capacity (note 1)	W	1000 ± 10%
Airflow rate	CFM	62 (typ.)
Rated voltage	VDC	48 (typ.)
Operating voltage range	VDC	40~60
Operating temperature range	°C	-40 ~ +65
Operating current	A	18.1
Acoustic noise at 1M :	dB-A	65 (typ.)
Weight	Kg (lb)	1.5 (3)
Heating element	/	PTC
Ingress Protection rating	IP	IP20 (IEC60529)

Note 1: The heating capacity (w) is @20 °C (68°F) ambient te

2.2835