


# HET400PA series

## Dimension drawing

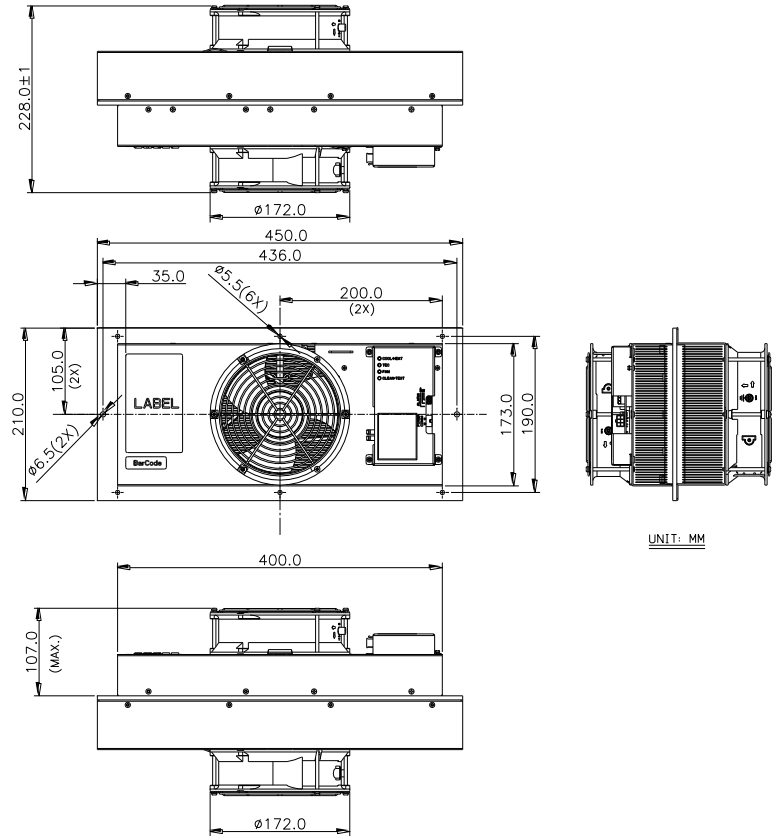

### Features

- ◆ IP55 waterproof at external side
- ◆ FAN / TEC / Control fail alarm
- ◆ Clear LED status indicator
- ◆ Standalone temperature control
- ◆ High efficiency and reliable fan modules

### Design

- ◆ High efficiency of cooling & Heating
- ◆ Thermal electric cooling module
- ◆ Rated voltage at 48V
- ◆ Built-in controller

Main feature	Unit	Specification
Dimension (H xW xD)	mm	480x 210x 228
Cooling capacity( $\Delta T=0^{\circ}\text{C}$ )	W	400 (TYP.)
Rated voltage	VDC	48 (TYP.)
Operating voltage range	VDC	40~56
Operating current	A	11.7
Power consumption	W	562
Operating temperature range	$^{\circ}\text{C}$	-40 ~ +55
Weight	Kg	11.0
Acoustic noise (1 meter)	dB-A	65

\* Specifications are subject to change without notice.