


Internal door mount

HEX010VA series



Dimension drawing

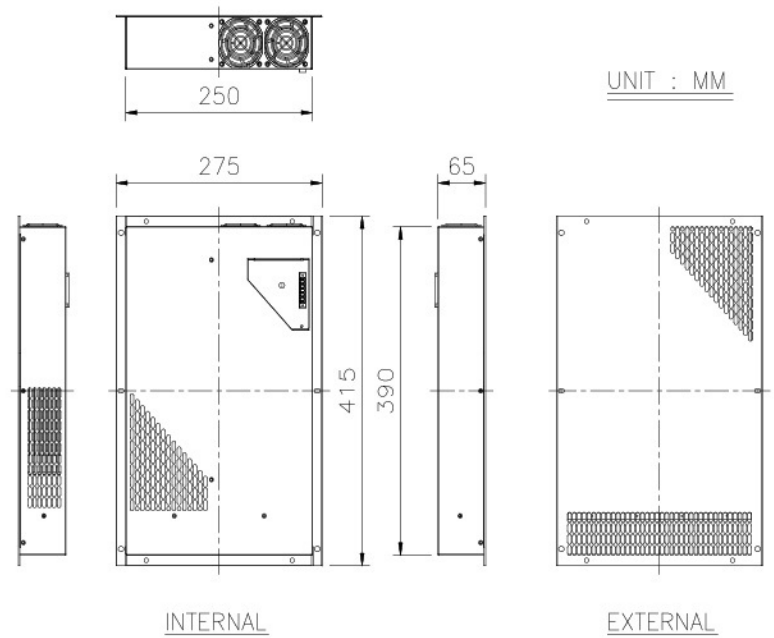

Features

- ◆ IP55 waterproof at external side
- ◆ Dry contact alarm output

Design

- ◆ Air to air heat exchange
- ◆ Rated voltage at 24V
- ◆ Redundant fan quantity design
- ◆ High efficiency and reliable fan
- ◆ Easy installation and maintenance

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	415 x 275 x 65 (16 x 11 x 2.6)
Cooling capacity*Note	W/K (W/°F)	10 (6)
Rated voltage	VDC	24
Operating current	A	1.2
Operating power	W	29
Operating voltage range	VDC	20 ~ 26
Operating temperature range	°C	-10 ~ +65
Noise (1.5 meter)	dB-A	61.0
Weight	Kg (Lb)	4 (9)

* Note : The cooling capacity (W/K , W/°C or W/°F) is defined as $Q / (T_I - T_A)$

Q : Heat dissipation (W) from inside of cabinet

T_I : Return temperature of internal air circuit (K , °C or °F)

T_A : Ambient temperature of external air circuit (K , °C or °F)

* Specifications are subject to change without notice.