


## Wall mount



## HEX015PA series

Dimension drawing

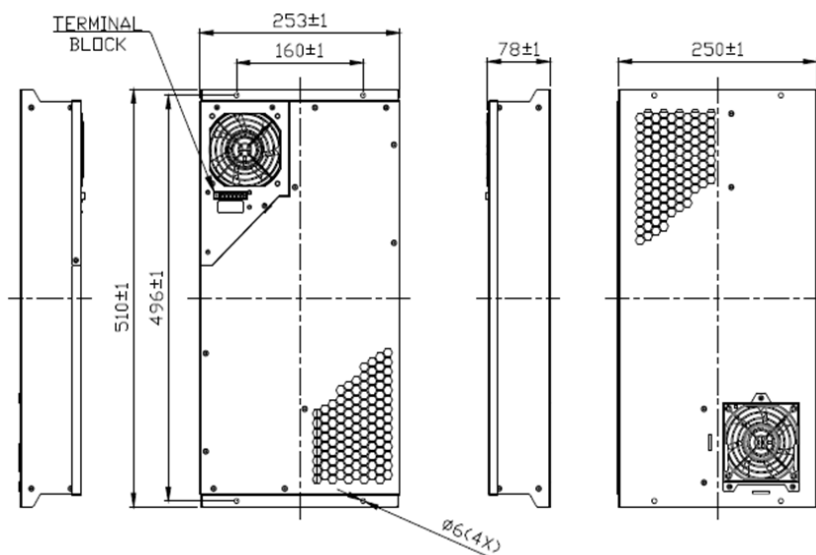

### Features

- ◆ Reliable and energy efficient thermal solutions.
- ◆ IP55 waterproof at external side.
- ◆ Dry contact alarm output.

### Design

- ◆ Compact size.
- ◆ Rated voltage at 48V.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	510H x 253W x 78D (20.1 x 10.0 x 3.1)
Cooling capacity	W/K	15 (8.3)
Rated voltage	VDC	48
Operating current	A	0.55
Operating Power	W	26.4
Operating voltage range	VDC	40 - 60
Operating temperature range	°C	-10 - +65
Noise (1.5 meter)	dB-A	62
Weight	Kg (Lb)	5.0 (11.0)

\* Specifications are subject to change without notice.