



## Wall mount

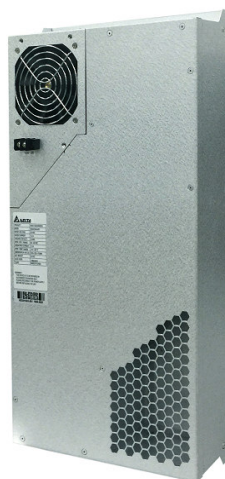

## HEX015VA series

Dimension drawing

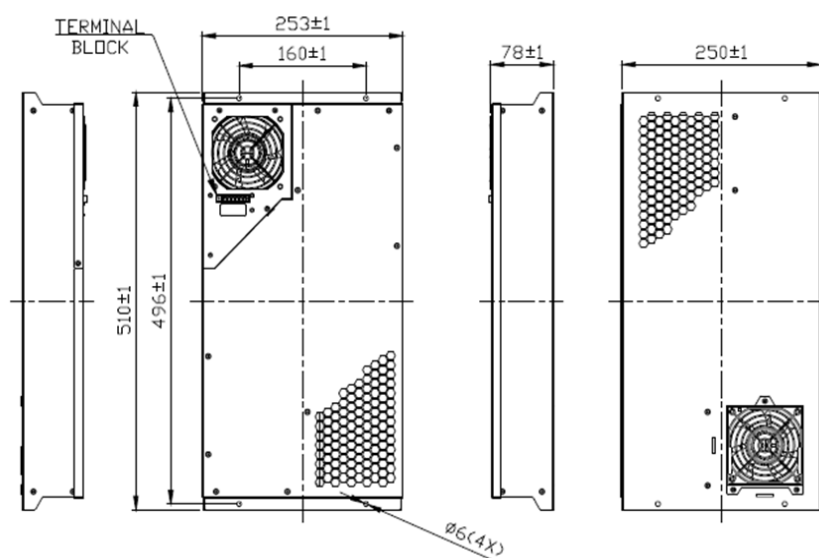

### Features

- ◆ Reliable and energy efficient thermal solutions.
- ◆ IP55 waterproof at external side.

### Design

- ◆ Compact size.
- ◆ Rated voltage at 24V.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	510H x 253W x 78D (20.1 x 10.0 x 3.1)
Cooling capacity	W/K	15 (8.3)
Rated voltage	VDC	24
Operating current	A	1.0
Operating Power	W	24
Operating voltage range	VDC	20 - 26
Operating temperature range	°C	-10 - +65
Noise (1.0 meter)	dB-A	65
Weight	Kg (Lb)	5.0 (11.0)

\* Specifications are subject to change without notice.