


## Internal door mount



## HEX020JA series

Dimension drawing

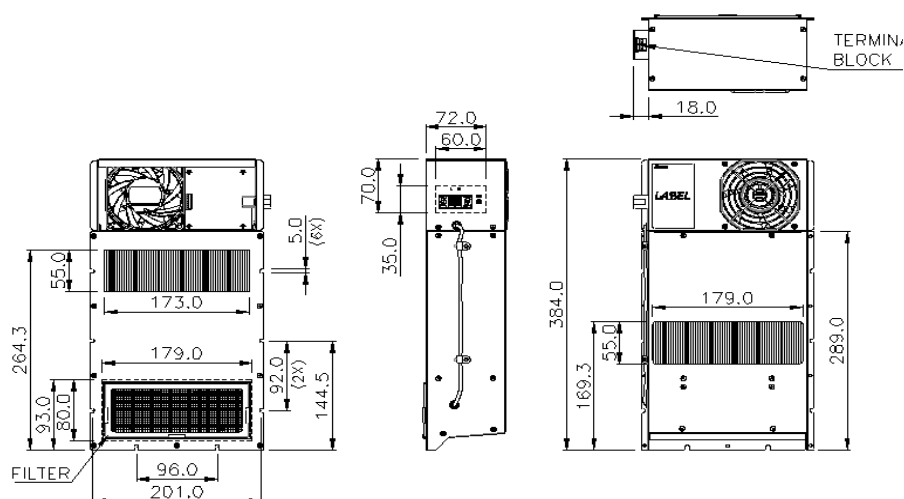

### Features

- ◆ IP54 waterproof at external side
- ◆ Compact size

### Design

- ◆ Air to air heat exchanger
- ◆ Rated voltage at 100 / 200 VAC
- ◆ High efficiency and reliable fan
- ◆ Easy installation and maintenance

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	384 x 205 x 95 (15.1 x 8.1 x 3.7)
Cooling capacity *Note	W/K (W/°F)	20 (11)
Rated voltage	VAC	100 / 200
Operating current	A	0.37 / 0.19
Operating power	W	37 / 38
Operating voltage range	VAC	100 - 240
Operating temperatur range	°C	-10 ~ +65
Noise (1.5 meter)	dB-A	65.0
Weight	Kg (Lb)	4 (8.8)

\*Note : The cooling capacity (W/K, W/°C or W/°F) is defined as  $Q/[(T_i+T_s)/2-T_A]$

Q : Heat dissipation (W) from inside of cabinet

T<sub>i</sub> : Return temperature of internal air circuit (K, °C or °F)

T<sub>s</sub> : Supply temperature of internal air circuit (K, °C or °F)

T<sub>A</sub> : Ambient temperature of external air circuit (K, °C or °F)

\*Specifications are subject to change without notice.