


Roof mount



HEX050QA series

Dimension drawing

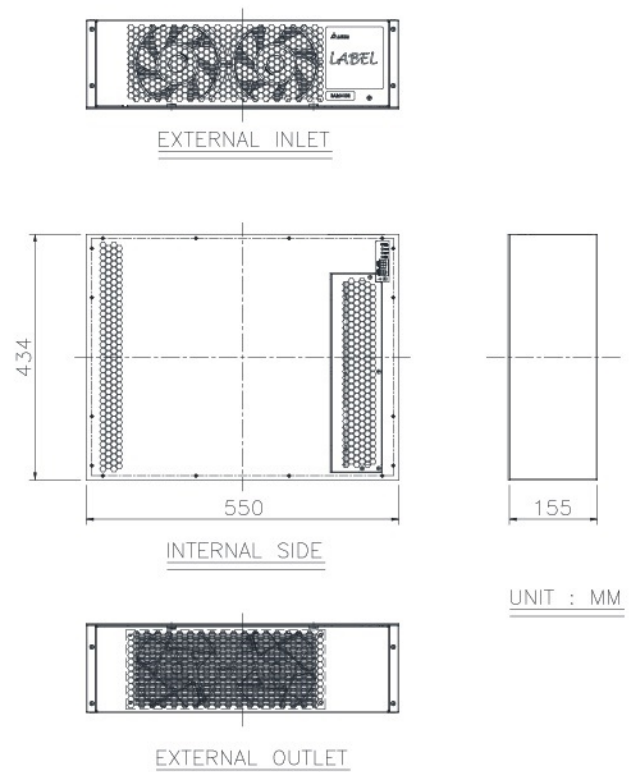

Features

- ◆ IP55 waterproof at external side
- ◆ "One touch" dry run test and dust cleaning
- ◆ Standalone temperature control
- ◆ Clear LED status indicator
- ◆ Dry contact alarm output

Design

- ◆ Air to air heat exchange
- ◆ Rated voltage at 48V
- ◆ Redundant fan quantity design
- ◆ High efficiency and reliable fan
- ◆ Easy installation and maintenance

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	155 x 550 x 434 (6 x 22 x 17)
Cooling capacity ^{*Note}	W/K (W/°F)	50 (28)
Rated voltage	VDC	48
Operating current	A	1.4
Operating power	W	68
Operating voltage range	VDC	40 ~ 60
Operating temperature range	°C	-10 ~ +65
Noise (1.5 meter)	dB-A	64.0
Weight	Kg (Lb)	9 (20)

* Note : The cooling capacity (W/K , W/°C or W/°F) is defined as $Q / (T_I - T_A)$

Q : Heat dissipation (W) from inside of cabinet

T_I : Return temperature of internal air circuit (K , °C or °F)

T_A : Ambient temperature of external air circuit (K , °C or °F)

* Specifications are subject to change without notice.