


Roof mount



HEX080QA series

Dimension drawing

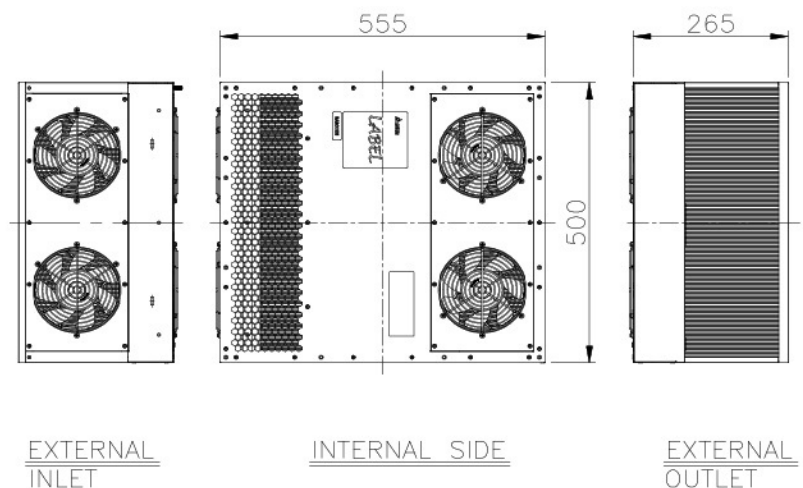

Features

- ◆ IP55 waterproof at external side
- ◆ "One touch" dry run test and dust cleaning
- ◆ Standalone temperature control
- ◆ Clear LED status indicator
- ◆ Dry contact alarm output

Design

- ◆ Air to air heat exchange
- ◆ Rated voltage at 48V
- ◆ Redundant fan quantity design
- ◆ High efficiency and reliable fan
- ◆ Easy installation and maintenance

| Main feature | Unit | Specification |
|-----------------------------------|------------|--------------------------------|
| Dimension (H x W x D) | mm (inch) | 265 x 555 x 500 (11 x 22 x 20) |
| Cooling capacity ^{*Note} | W/K (W/°F) | 80 (44) |
| Rated voltage | VDC | 48 |
| Operating current | A | 1.5 |
| Operating power | W | 72 |
| Operating voltage range | VDC | 40 ~ 60 |
| Operating temperature range | °C | -10 ~ +65 |
| Noise (1.5 meter) | dB-A | 64.0 |
| Weight | Kg (Lb) | 22 (49) |

* Note : The cooling capacity (W/K , W/°C or W/°F) is defined as $Q / (T_I - T_A)$

Q : Heat dissipation (W) from inside of cabinet

T_I : Return temperature of internal air circuit (K , °C or °F)

T_A : Ambient temperature of external air circuit (K , °C or °F)

* Specifications are subject to change without notice.