


External mount



HEX100PG series

Dimension drawing

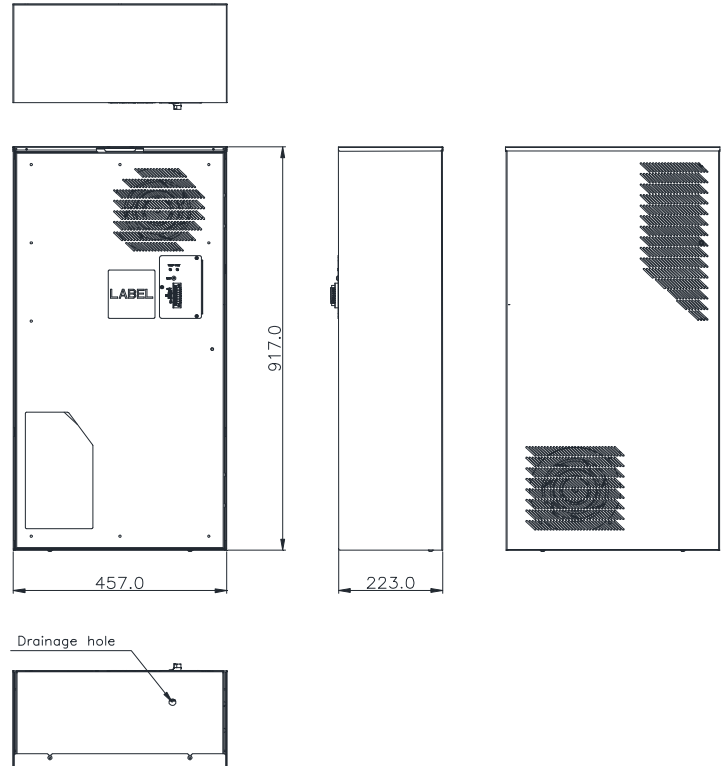

Features

- ◆ Reliable and energy efficient thermal solutions.
- ◆ IP55 waterproof at external side.
- ◆ Dry contact alarm output.
- ◆ Remote control (optional)

Design

- ◆ Compact size.
- ◆ Rated voltage at 48V.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	917H x 457W x 223D (36 x 18 x 8.8)
Cooling capacity	W/K	99
Rated voltage	VDC	48
Operating current	A	4.3
Operating Power	W	206
Operating voltage range	VDC	40 - 60
Operating temperature range	°C	-40 - +65
Noise (1.5 meter)	dB-A	69
Weight	Kg	27

* Specifications are subject to change without notice.