
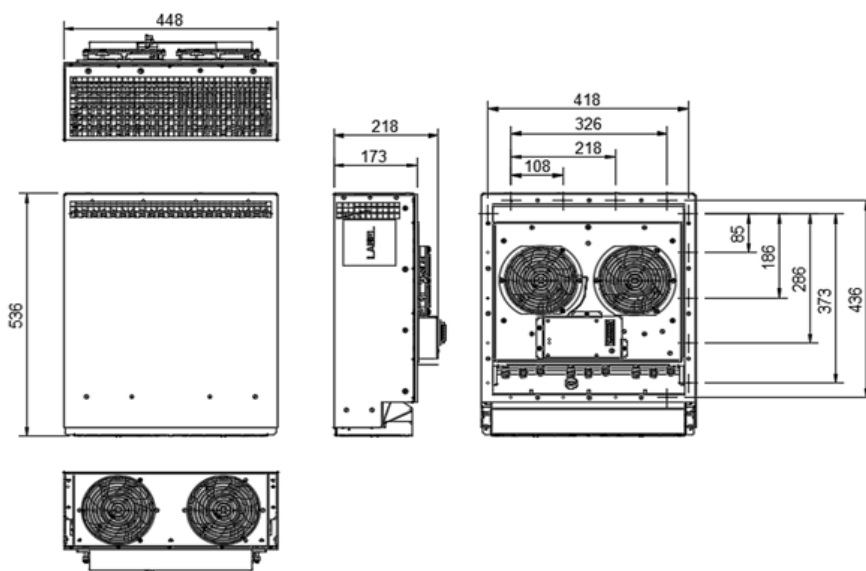


External mount

HEX110QA series

Dimension drawing

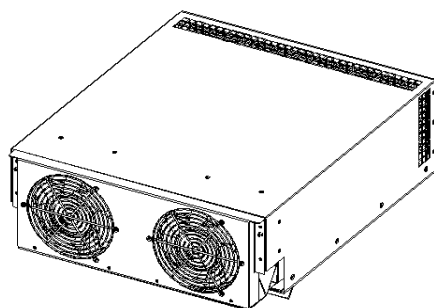

Features

- ◆ IP55 waterproof at external side.
- ◆ Standalone temperature control.
- ◆ RS-485 function (Optional).
- ◆ Dry contact alarm output.

Design

- ◆ Rated voltage at 48V.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.
- ◆ Refrigerant R134a used.

Main feature	Unit	Specification
Dimension (H x W x D) (without flange)	mm (inch)	536 x 448 x 218 (21.1 x 17.6 x 8.7)
Cooling capacity	W/K	100
Rated voltage	VDC	48
Operating current	A	4.0
Operating voltage range	VDC	40 - 60
Operating temperature range	°C	-10 - +55
Noise (1.5 meter)	dB-A	75
Weight	Kg (Lb)	15 (33.1)

* Specifications are subject to change without notice.