
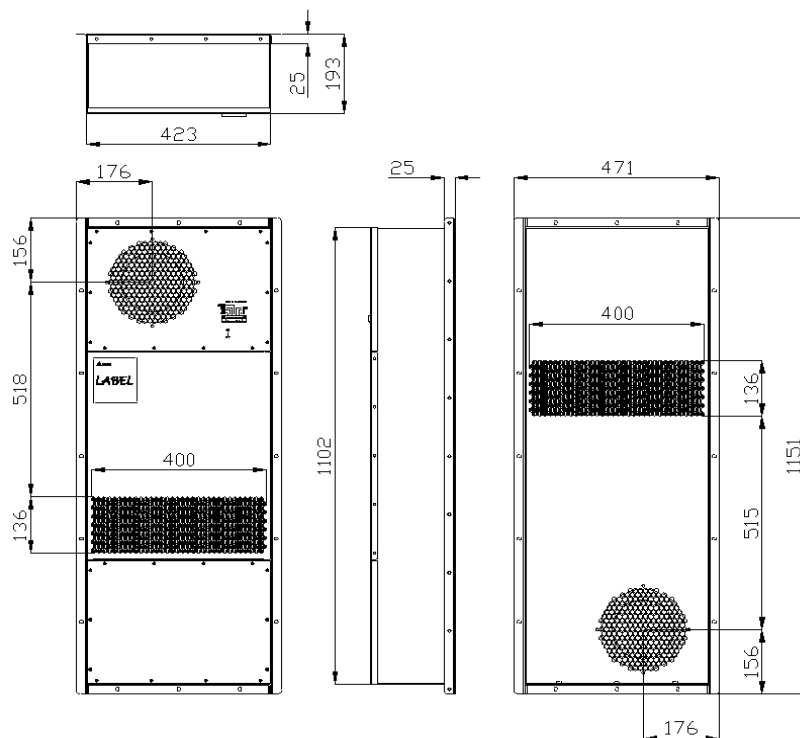


Internal mount

HEX120PA series

Dimension drawing

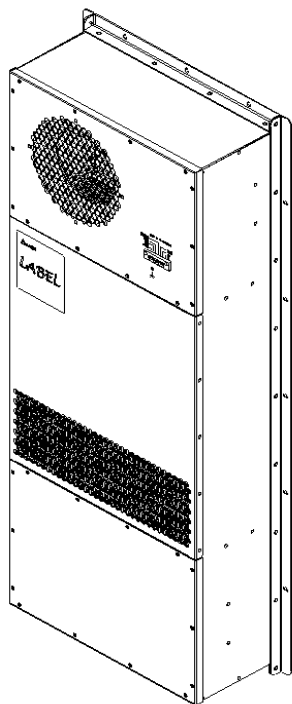

Features

- ◆ IP55 waterproof at external side.
- ◆ Standalone temperature control.
- ◆ RS-485 function (Optional).
- ◆ Dry contact alarm output.

Design

- ◆ Rated voltage at 48V.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

Main feature	Unit	Specification
Dimension (H x W x D) (without flange)	mm (inch)	1102 x 423 x 193 (43.3 x 16.7 x 7.6)
Cooling capacity	W/K	120
Rated voltage	VDC	48
Operating current	A	4.4
Operating voltage range	VDC	40 - 60
Operating temperature range	°C	-40 - +65
Noise (1.5 meter)	dB-A	64
Weight	Kg (Lb)	33 (72)

* Specifications are subject to change without notice.