

Wall mount



Features


- ◆ IP55 waterproof at external side.
- ◆ Standalone temperature control
- ◆ RS-485 function (optional)
- ◆ Clear LED status indicator
- ◆ Dry contact alarm output.
- ◆ R134a Refrigerant

Design

- ◆ Air to air heat exchange
- ◆ Rated voltage at 48V.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

HEX120PD series

Dimension drawing

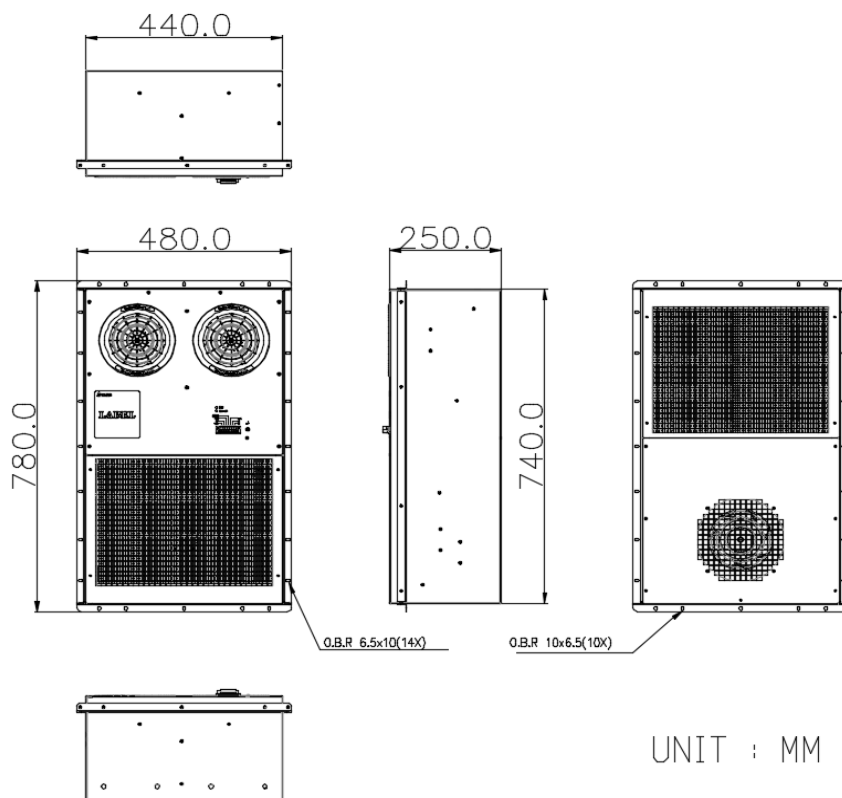

Main feature	Unit	Specification
Dimension (H x W x D)	mm (in)	740H x 440W x 250D (29 x 17 x 10)
Cooling capacity	W/K (W/F)	120 (67)
Rated voltage	VDC	48
Operating current	A	2.9
Operating Power	W	139
Operating voltage range	VDC	40 - 60
Operating temperature range	°C	-20 - +65
Noise (1.5 meter)	dB-A	64
Weight	Kg	21

* Specifications are subject to change without notice.