


Door mount



HET100VA

Dimension drawing

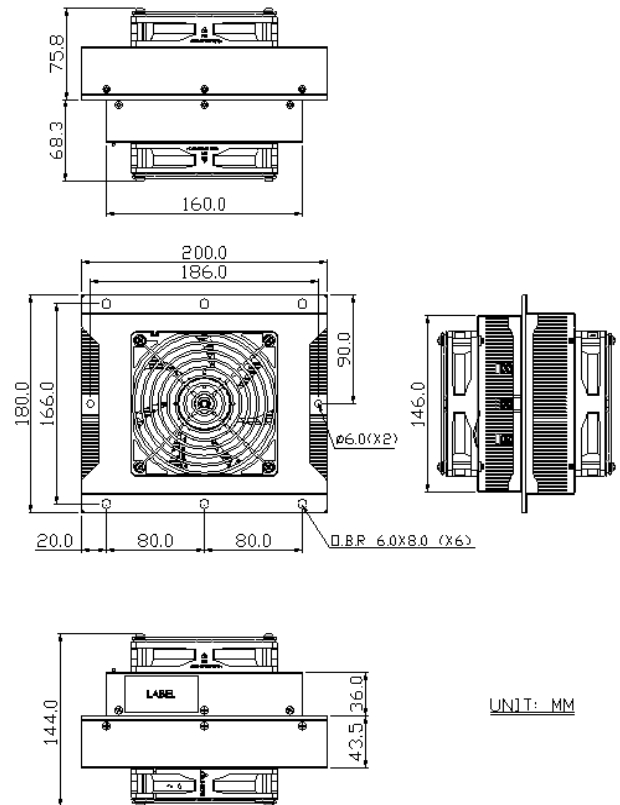

Features

- ◆ IP55 waterproof at external side.
- ◆ High efficiency and reliable fan modules.

Design

- ◆ High efficiency of cooling & heating.
- ◆ Thermal electric cooling module.
- ◆ Rated voltage at 24V.

Main feature	Unit	Specification
Outline dimension (H x W x D)	mm (inch)	200 x 180 x 144 (7.9 x 7.1 x 5.7)
Weight	Kg	3.0 ± 0.5
Cooling Capacity ($\Delta T = 0^{\circ}\text{C}$)	W	100 (TYP.)
Heating capacity @-40°C	W	112
Rater voltage	VDC	24 (TYP.)
Operating voltage range	VDC	20~26
Actuality Current	A	5.9 (TYP.)
Power Consumption	W	283
Operating temperature	°C	-40~55
Acoustic noise at 1m	dB-A	61.0 (Typ.), 65 (Max)