 


DIN-Rail Mount




Airflow orientation

Features

- ◆ Quick heating
- ◆ Constant Air Flow
- ◆ Compact design
- ◆ High efficiency and reliable DC fan
- ◆ Overheat & short protect function
- ◆ Keep surface temperature <70°C
- ◆ Touch-safe

HEH030BB series

Dimension drawing

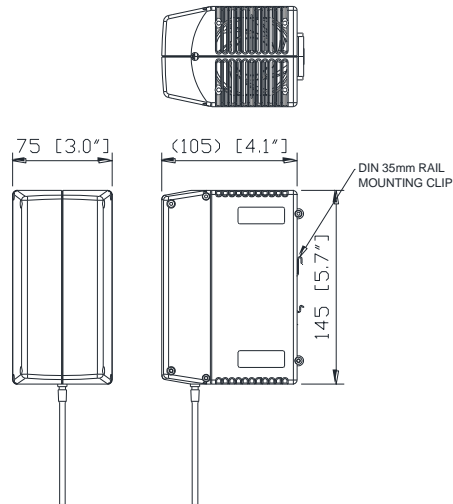

Main feature	Unit	Specification
Outline Dimension	mm (inch)	145Hx 75W x 105D (5.7 x 3.0 x 4.1)
Heating Capacity (note 1)	W	300 ± 10%
Airflow rate	CFM	43 (typ.)
Rated voltage	VAC	220 (typ.)
Operating voltage range	VAC	198 - 242
Operating temperature range	°C (°F)	-40 to +60 (-40 to +140)
Operating current	A	<1.65 (with fan)
Acoustic noise at 1M :	dB-A	54 (typ.)
Weight	Kg (lb)	0.6 (1.32)
Heating element	/	Semiconductor
Ingress Protection rating	IP	IP20 (IEC60529)

Note 1: The heating capacity (w) is defined as power consumption.