



Wall Mount

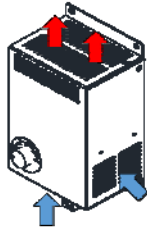

Airflow orientation

HEH080BB series

Dimension drawing

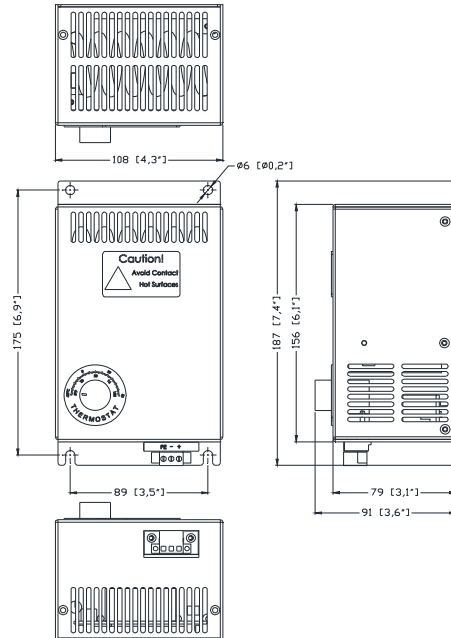

Features

- ◆ Quick heating
- ◆ Constant Air Flow
- ◆ Compact design
- ◆ High efficiency and reliable DC fan
- ◆ Overheat & short protect function
- ◆ Keep surface temperature <70°C
- ◆ Adjustable Temp. setting -20~+40°C(-4~+104°F)

Main feature	Unit	Specification
Outline Dimension	mm (inch)	187Hx 108W x 79D (7.4 x 4.3 x 3.1)
Heating Capacity (note 1)	W	800 ± 10%
Airflow rate	CFM	35 (typ.)
Rated voltage	VAC	230 (typ.)
Operating voltage range	VAC	207 - 253
Operating temperature range	°C (°F)	-30 to +40 (-22 to +104)
Operating current	A	<3.5 (with fan)
Acoustic noise at 1M :	dB-A	54 (typ.)
Weight	Kg (lb)	0.8 (1.8)
Heating element	/	Cartridge
Ingress Protection rating	IP	IP20 (IEC60529)

Note 1: The heating capacity (w) is defined as power consumption.