


## Bottom Mount

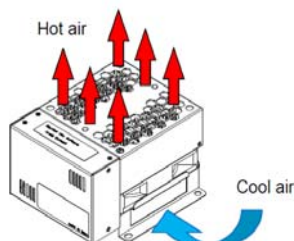


Airflow orientation

### Features

- ◆ Quick heating
- ◆ Constant Air Flow
- ◆ Compact design
- ◆ High efficiency and reliable DC fan
- ◆ Overheat & short protect function
- ◆ Keep surface temperature <70°C

## HEH095BA series

### Dimension drawing

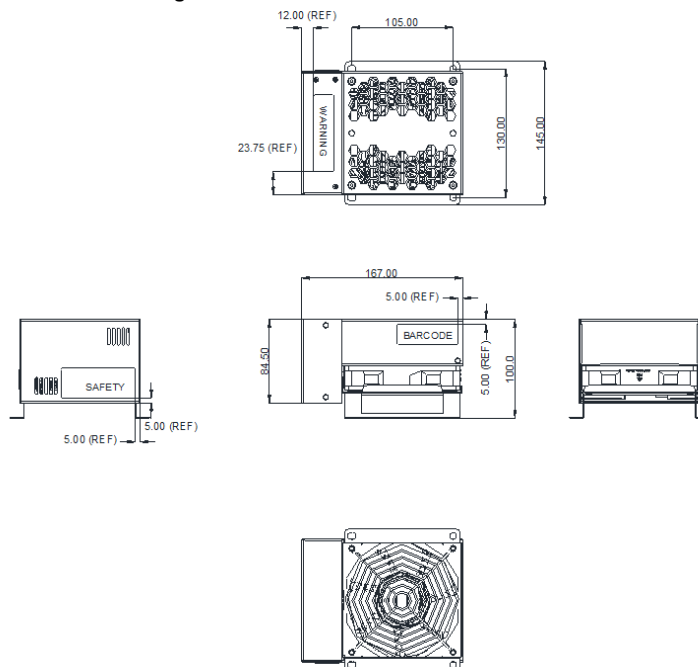

Main feature	Unit	Specification
Outline Dimension	mm (inch)	100L x 145W x 167D (3.9 x 5.7 x 6.6)
Heating Capacity (note 1)	W	950 ± 10%
Airflow rate	CFM	70 (typ.)
Rated voltage	VAC	230(typ.)
Operating voltage range	VAC	189 - 264
Operating temperature range	°C	-40 ~ +35
Operating current	A	<4.5 (with fan)
Acoustic noise at 1M :	dB-A	54 (typ.)
Weight	Kg (lb)	1.5 (3)
Heating element	/	Cartridge
Ingress Protection rating	IP	IP20 (IEC60529)

Note 1: The heating capacity (w) is defined as power consumption.

\* Specifications are subject to change without notice.