

## Wall mount




## HEH100PA series

### Dimension drawing

#### NOTE :

- (1) Material : SGCC T=1.0mm
- (2) Finish : Powder paint 75~120um, Color 7032
- (3) Dimensional tolerance :  $\pm 1.0\text{mm}$

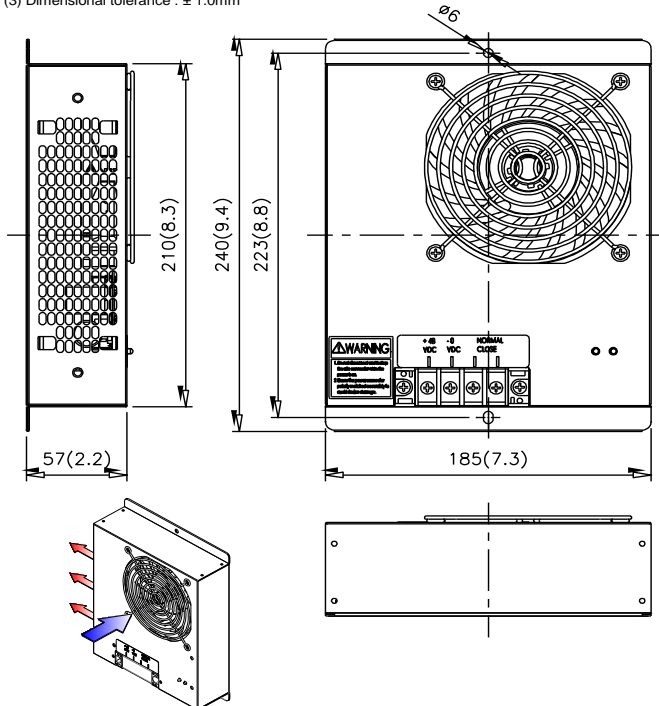

### Features

- ◆ Quick heating
- ◆ Constant Air Flow
- ◆ Dry contact control
- ◆ Component fail alarm
- ◆ Compact design
- ◆ Soft Start
- ◆ High efficiency and reliable fan
- ◆ Easy installation

Main feature	Unit	Model Number
		HEH100PA
Outline dimension	mm	240 H x 185 W x 57 D
Weight	kg	1.5 $\pm$ 0.5
Heating Capacity	W	1000 $\pm$ 10%
Rated voltage	Vdc	48 (typ.)
Operating voltage range	Vdc	40-60
Operating status	N/A	LED indicator
Fan /Heater fail alarm	N/A	Dry contact output

\* Specifications are subject to change without notice.