
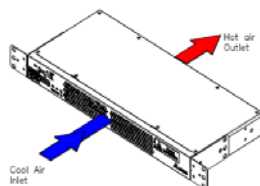


## Rack Mount

## HEH100PB

### Dimension drawing

NOTE:  
 (1) Material : SGCC T=1.0mm  
 (2) Finish : Powder paint 75~120um, Color RAL 7032  
 (3) Dimensional tolerance :  $\pm 1.0\text{mm}$

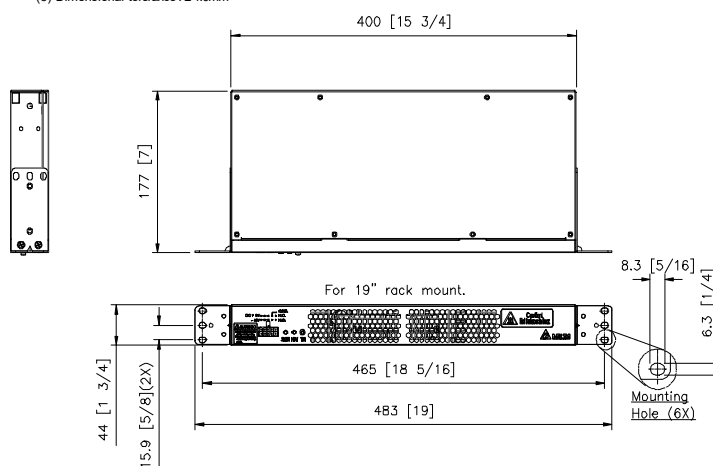

### Features

- ◆ Quick heating
- ◆ Constant Air Flow
- ◆ Standalone temperature control
- ◆ Component fail alarm
- ◆ Compact design
- ◆ Two step heating
- ◆ High efficiency and reliable fan
- ◆ 1U rack use

Main feature	Unit	Specification
		HEH100PB
Outline Dimension	mm	44 H x 483 W x 177 D
Weight	kg	2.5 +/- 0.5
Heating Capacity	W	1000 $\pm$ 20%
Rated voltage	Vdc	48 (typ.)
Operating voltage range	Vdc	46-56
Operating status	N/A	LED indicator
Fan / Heater fail alarm	N/A	Dry contact output
Inrush current	A	28

\*Specifications are subject to change without notice.