


Wall mount



HEC1000AFR series

Dimension drawing

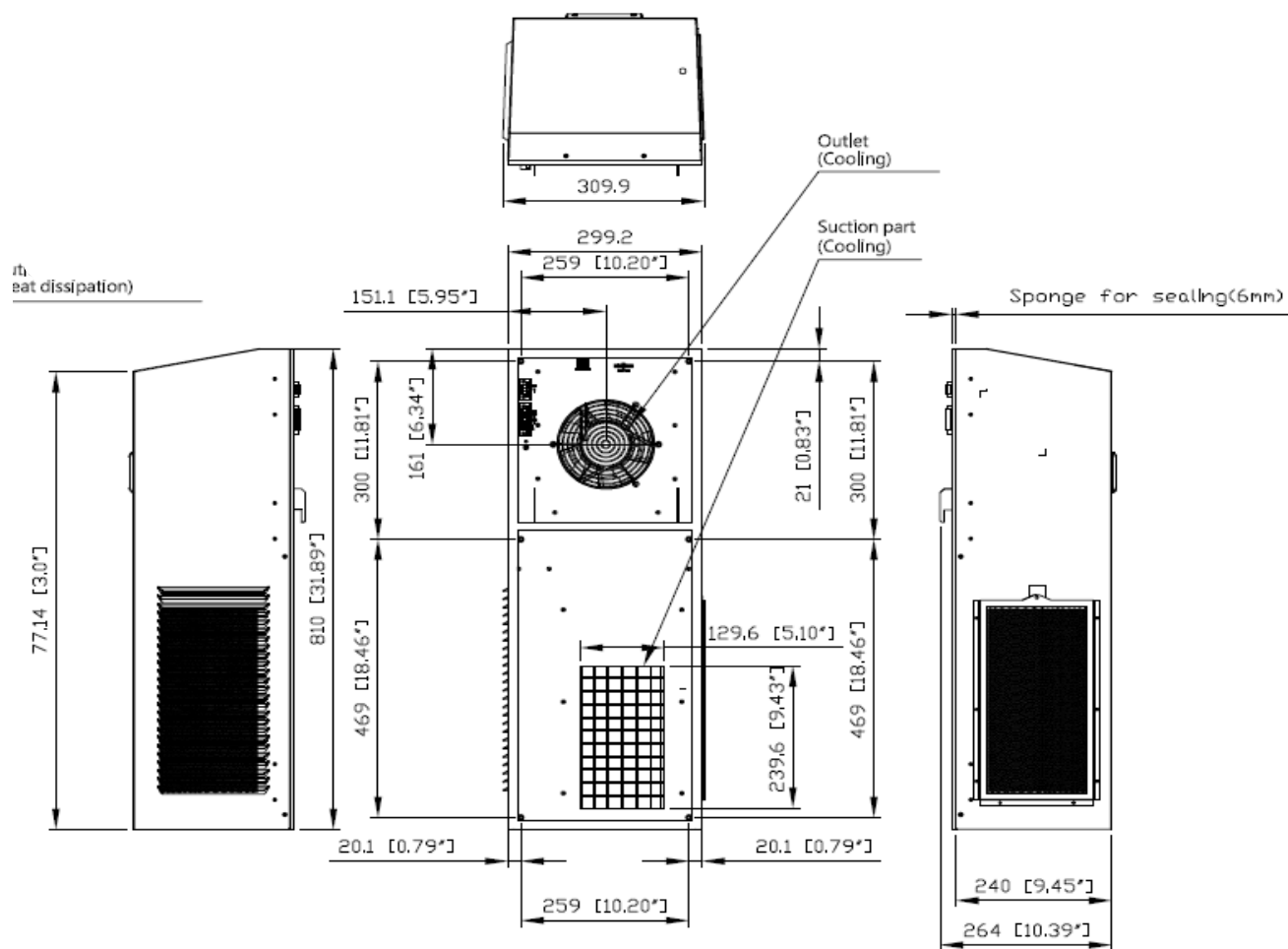

Features

- ◆ Reliable and energy efficient thermal solutions.
- ◆ Energy efficient fans and effective compressor.
- ◆ UL type 4X waterproof at external side.
- ◆ Precise temperature control.
- ◆ Earth-friendly refrigerant.
- ◆ Dry contact alarm output.
- ◆ Remote control function

Design

- ◆ Compact size.
- ◆ Rated voltage at 115 VAC.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	810 x 299 x 240 (32" x 11.8" x 9.5")
Cooling capacity*Note	W (BTU/hr)	1000(3143)
Rated voltage	VAC	115
Operating current	A	4.2
Operating voltage range	VAC	105 ~ 127
Operating temperature range	°C	-10 ~ +55
Noise (1.0 meter)	dB-A	65
Weight	Kg (Lb)	27 (50.7)

* Note : L35/L35, AC 115V/60HZ

* Specifications are subject to change without notice.