


## Wall mount



## HEC1000BAS series

### Dimension drawing

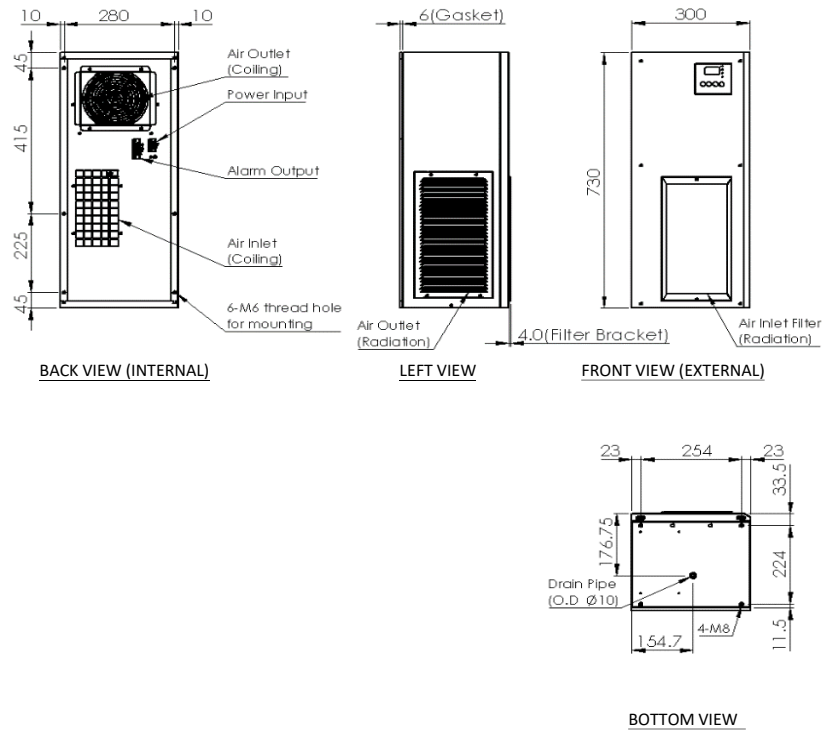

Unit : mm

### Features

- ◆ Reliable and energy efficient thermal solutions
- ◆ Energy efficient fans and effective compressor
- ◆ IP55 waterproof at external side
- ◆ Precise temperature control
- ◆ Earth-friendly refrigerant (GWP <7)
- ◆ Dry contact alarm output
- ◆ Remote control function

### Design

- ◆ Compact size
- ◆ Rated voltage at 200 ~ 240 VAC
- ◆ Built-in smart controller
- ◆ High efficiency and reliable fan
- ◆ Easy installation and maintenance

| Main feature                | Unit       | Specification                           |
|-----------------------------|------------|---|
| Dimension (H x W x D)       | mm (inch)  | 730 x 300 x 270 (28.78 x 11.81 x 10.63) |
| Cooling capacity*Note       | W (BTU/hr) | 1000 (3412)                             |
| Rated voltage               | VAC        | 200 ~ 240                               |
| Operating current           | A          | 2.2                                     |
| Operating voltage range     | VAC        | 180 ~ 264                               |
| Operating temperature range | °C         | -10 ~ +55                               |
| Noise (1.0 meter)           | dB-A       | 65                                      |
| Weight                      | Kg (Lb)    | 26 (57.3)                               |

\* Note : L35/L35

\* Specifications are subject to change without notice.