


Wall mount



HEC1000BFR series

Dimension drawing

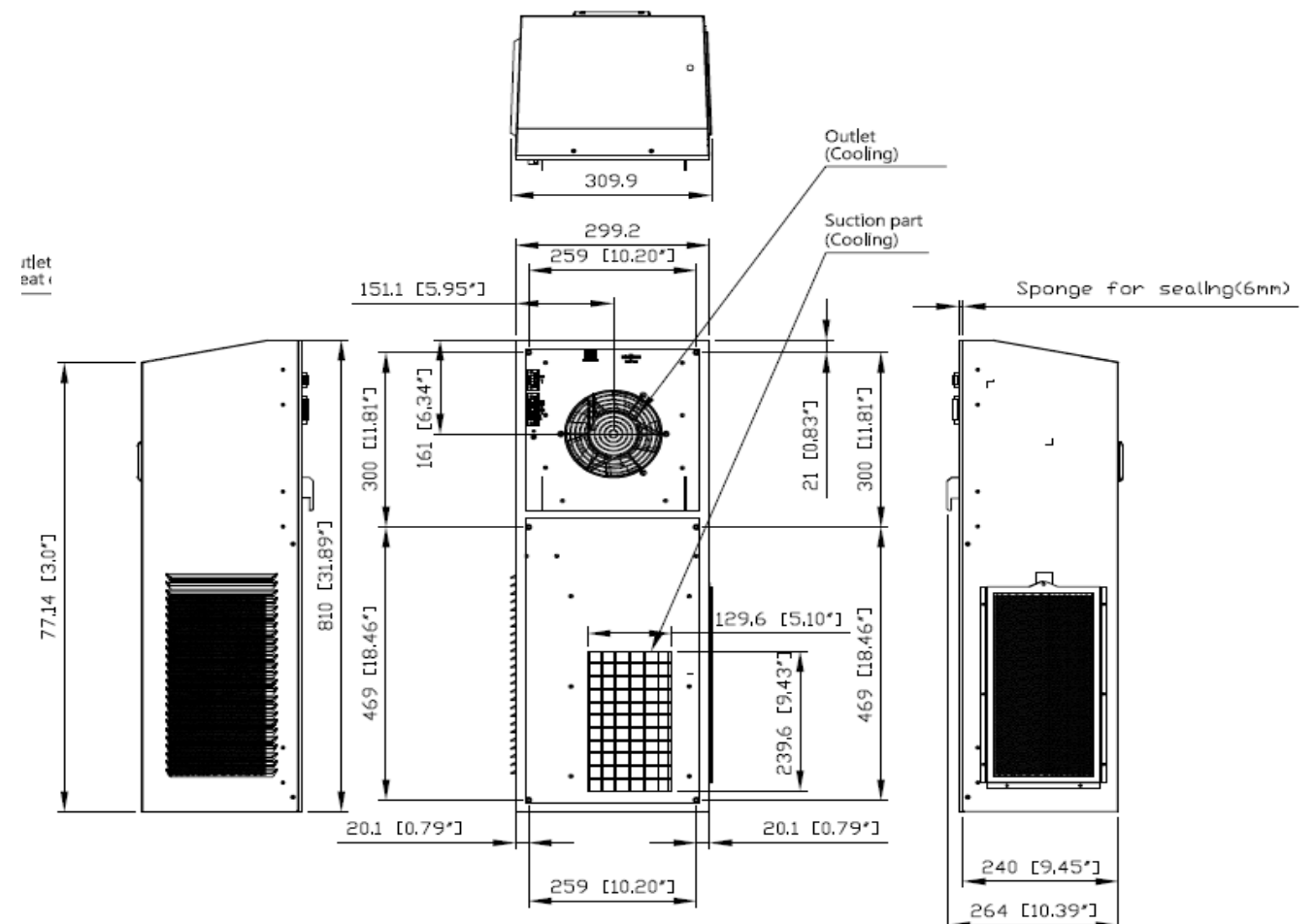

Features

- ◆ **Reliable and energy efficient thermal solutions.**
- ◆ **Energy efficient fans and effective compressor.**
- ◆ **UL type 4X waterproof at external side.**
- ◆ **Precise temperature control.**
- ◆ **Earth-friendly refrigerant.**
- ◆ **Dry contact alarm output.**
- ◆ **Remote control function**

Design

- ◆ **Compact size.**
- ◆ **Rated voltage at 230 VAC.**
- ◆ **Built-in smart controller.**
- ◆ **High efficiency and reliable fan.**
- ◆ **Easy installation and maintenance.**

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	810 x 299 x 240 (32" x 11.8" x 9.5")
Cooling capacity*Note	W (BTU/hr)	1000(3143)
Rated voltage	VAC	230
Operating current	A	1.88
Operating voltage range	VAC	207~253
Operating temperature range	°C	-10 ~ +55
Noise (1.0 meter)	dB-A	65
Weight	Kg (Lb)	27 (50.7)

* Note : L35/L35, AC230V/60HZ

*** Specifications are subject to change without notice.**