

Applications



Factory




Warehouse



Big Box Retailer



Gymnasium

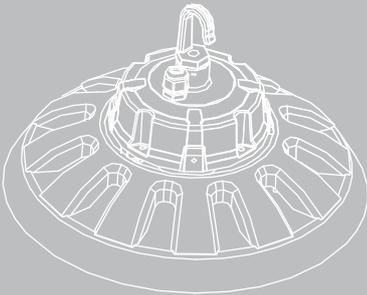

SCDJ series

Delta's SCDJ series is an industrial leading LED High/Low Bay luminaire that can replace MH fixtures up to 400W with as low as 7 lbs weight. With the elegant outlook and glare free (UGR<19) design, SCDJ high bay fixtures are suitable for both commercial and industrial lighting applications. Thanks to Delta's advanced programmable driver, the lumens output can be adjusted and also possible to achieve constant light output.


Features

- High efficacy and ultra-light in weight ~ 8 lbs
- Various functions can be programmed, including dimming curve, scheduled dim and dim to off
- Available in constant light output
- Operation hours calculation optional
- Available in DALI control
- Auxiliary 12Vdc output power for extended control features
- Excellent optics design for high spacing criteria (~1.5)
- Hook, pendant and bracket mountings
- Optional reflector for light quality enhancement
- L70 > 100,000hours (Nichia LED) and 0-10V dimming.
- Glare Free (UGR<19)


Model Name	Power (W)	Input Voltage	CCT (K)	CRI (Ra)	Beam Angle	Lumen Output	Efficacy (lm/W)
SCDJI5H00U	160	120-277 Vac	5000	> 80	100°	22,000 lm	138
SCDJI4H00U	160	120-277 Vac	4000	> 80	100°	21,500 lm	134
SCDJD5H00U	130	120-277 Vac	5000	> 80	100°	18,500 lm	142
SCDJD4H00U	130	120-277 Vac	4000	> 80	100°	18,000 lm	138
SCDJ85H00U	85	120-277 Vac	5000	> 80	100°	12,500 lm	147
SCDJ84H00U	85	120-277 Vac	4000	> 80	100°	12,000 lm	141

• Other Beam Angle Available: 60D • Mounting: Hook and pendant via the included junction box

Light Distribution

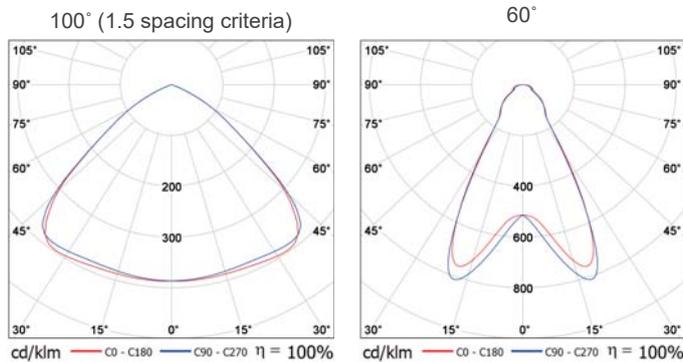

Dimension

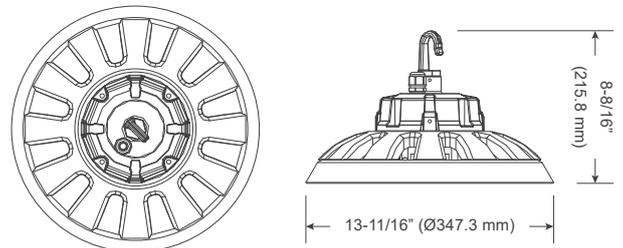

Accessories

