


Common Chokes

EMI Common-Mode Suppression Inductors

HFZ24H Type

Mechanical Dimension: Unit: mm

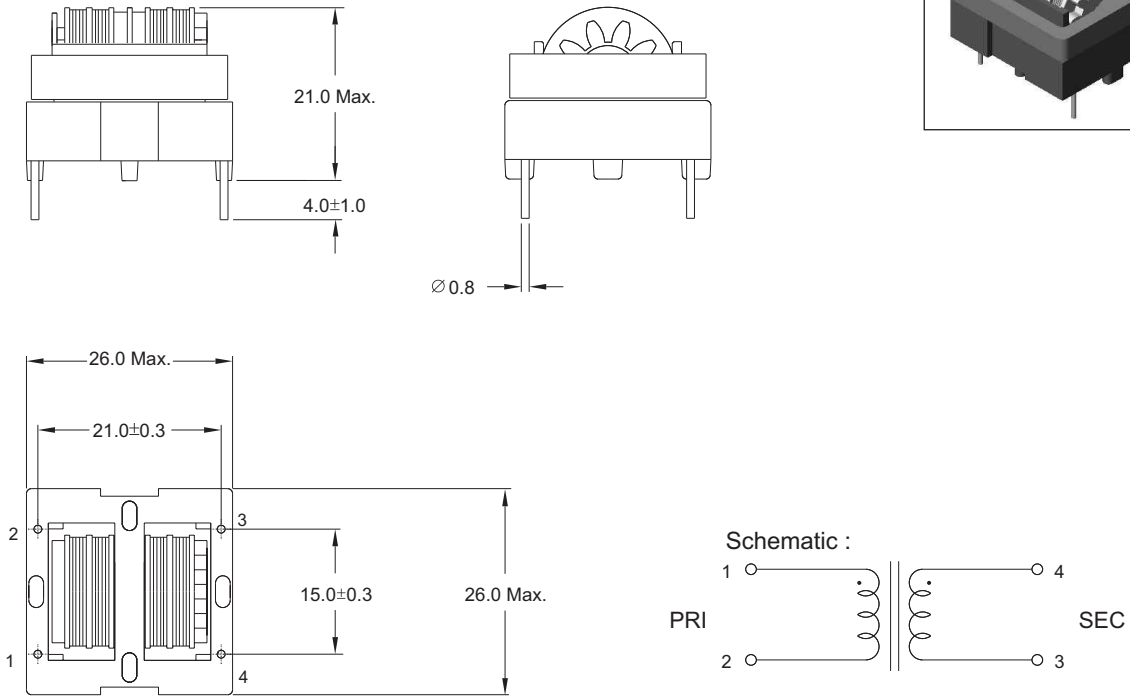

Electrical Characteristics:

■ AT 25°C, 40KHz/1V Tested:

PART NO.	INDUCTANCE (mH) MIN	DCR (mΩ) MAX	RATED CURRENT (Aac)	TEMPERATURE RISE (°C) MAX
HFZ24H01	78.0	2015	0.3	45
HFZ24H02	68.0	1815	0.4	45
HFZ24H03	54.5	1390	0.5	45
HFZ24H04	35.0	930	0.6	45
HFZ24H05	22.0	550	0.9	45
HFZ24H06	18.0	490	1.0	45
HFZ24H07	14.7	360	1.1	45
HFZ24H08	9.9	250	1.4	45
HFZ24H09	8.1	220	1.5	45
HFZ24H10	6.0	155	1.8	45
HFZ24H11	4.4	115	2.0	45
HFZ24H12	2.9	87	2.4	45

* WITHSTANDING VOLTAGE BETWEEN L1 & L2 1.5KV 1 MINUTE
* GOOD DIFFERENCE IN WINDING L1 & L2 INDUCTANCE



DELTA ELECTRONICS, INC.

(TAOYUAN PLANT CPBG) 252, SAN YING ROAD, KUEISAN INDUSTRIAL ZONE, TAOYUAN SHIEN, 333, TAIWAN, R.O.C.

TEL: 886-3-3591968; FAX: 886-3-3591991

<http://www.deltawww.com>