



LCD Video Wall


55" Ultra Narrow Bezel LCD Video wall

- Full HD (1920 x 1080) Resolution
- 3.5mm Combined Bezel
- Full Array LED Backlighting
- Support up to 10x10 Display Array



Ultra Narrow Bezel LCD Video Wall

Delta's Ultra Narrow Bezel (UNB) LCD video wall features full HD resolution and direct LED backlights ensuring crystal clear image and long life. With a combined bezel width of 3.5mm, Delta's Ultra Narrow LCD provides a near seamless image, ideal for public venues and control rooms.

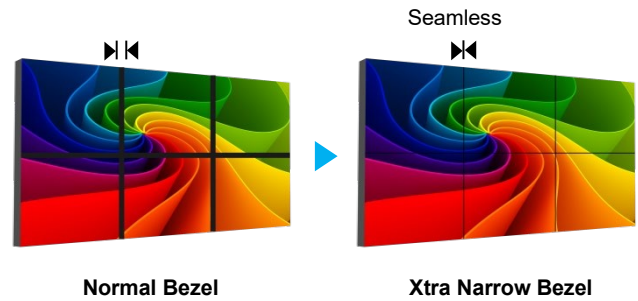

Specifications

Model	LW-5582 LR KC IR
Panel	55 inch Ultra Narrow Bezel
Bezel to Bezel	3.5mm
Back Light Type	Direct LED
Resolution	Full HD 1920 x 1080, professional-grade display, 24/7
Pixel Pitch	0.63(H) x 0.63(V)mm
Display Colors	1.07 Billion
Luminance of White	Typical 500 nits
Contrast Ratio (Full On/Off)	1400:1
Viewing Angle(CR>10)	178 (H), 178 (V)
Response Time	Typical 8 ms
Inputs	1 x Digital DVI-D [3840x216@30Hz]
	2 x HDMI 2.0 [3840x2160@60Hz] / 1.4 [3840x2160@30Hz] Audio in/out
	1 x VGA (1920x1080@60Hz) interface DB15
	1 x DP (3840x2160@30Hz)
	1 x USB 2.0 for Multi-Media
Output	2 x Ethernet RJ45 – 1x in/1x out (RS232) for control
	1 x Digital DVI-D (DVI IN/DP IN/HDMI2 loop-out)
Power Control	AC power ON/OFF switch
Wire Control	RS232C input
AC Power Input Range	100~240VAC, 50/60Hz
Power Consumption	On Mode : typical ≤170W with 1 DVI input
	Standby Mode : < 0.5 W
Dimension (W x H x D)	1213.4 x 684.2 x 100.0mm @VESA mount (121.1mm with handles), Net weight : 24.5Kg
Operating Temperature	0°C to 40°C
Storage Temperature	-10°C to +60°C
Working Humidity	10% - 85%, non-condensing
Backlight Operating Life	Min 60,000 hours

※ All specifications are subject to change without prior notice.