



LED Panel Lighting

Albedo Eco Back-Lit (BL) IP54

Energy-efficient & power adjustable

- Slim and lightweight panel for easy installation and maintenance
- Robust panel with IP54
- UGR19 with micro prismatic diffuser
- System efficiency up to 140 lm/W
- Adjustable power switch on the driver
- Best flicker free lighting
- Simple Plug & Play connector
- 5 years warranty

Applications



Offices










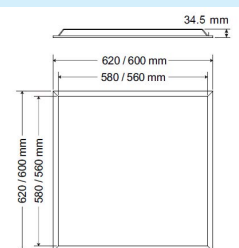
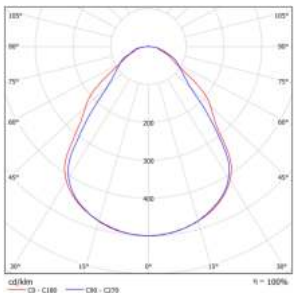
Commercial



Retail



Healthcare

	LSHD05P54R6340-ML	LSHD05P54RG340-ML
Lumen Output (lm)	3300 / 3900 / 4500 / 5000	
Power (W)	24 / 28 / 32 / 36 (switchable)	
Efficacy (lm/W)	up to 140	
CRI	>80	
CCT	4000K	
Operating Temperature	- 20° to +40°C	
Lifetime	L80B10> 50 000h at Ta=25°C	
Input Voltage	220-240 V	
UGR	<19	
Ingress Protection	IP20 (back side) / IP54 (room side)	
Impact Resistance	IK02	
Power Factor	>0.9	
Electrical Safety Class	Class II	
Photo-biological Safety	RG0	
Color Tolerance (MacAdam)	< 4 SDCM	
Weight (kg)	1.8	2
Product Dimension (mm)	595 * 595 * 34.5	620* 620 * 34.5
Control Interface	ON/OFF - DALI 2 (optional)	
Accessories & options	 Safety cable (included)  Suspension kit LSHD05PAC0022  Surface mounting frame 600*655*67 mm LSHD05PAC0021  Surface mounting frame 624*680*67 mm LSHD05PAC0027  Emergency kit LSHD05PAC0024  Recessed mounting frame 625*625*40 mm LSHD05PAC0028  Recessed mounting frame 650*650*40 mm LSHD05PAC0029	
Dimension		
Photometry		
Remark	More technical information : Glow Wire Test at 650°C / 1kV Surge Protection / Flickering <3% at 100Hz / THD<20%	

Delta Electronics (Netherlands) B.V.

Zandsteen 15, 2132 MZ Hoofddorp, The Netherlands

E: sleu@deltaww.com

T: +31-20-655-0900