

Linear LED Lighting

Altos Tubular Gen2

IP69K version

- IP69K and IK10 high protection level
- Best flicker free light quality with very long lifetime
- High luminous efficacy of 160 lm/W
- Motion sensor and DALI 2.0 optional
- Excellent visual comfort and uniformity of light thanks to a unique design
- Through-wiring optional for linking luminaires
- 5 years warranty

Applications



Industrial



Parking







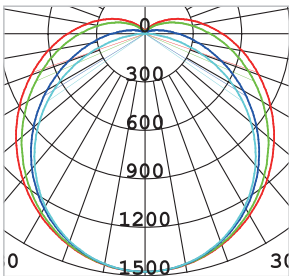

Warehouse



Work Area

www.deltaww-emea.com/ledlighting



	LSHD04TUBS2240-I69	LSHD04TUBS4340-I69	LSHD04TUBS5440-I69	LSHD04TUBS2230-I69	LSHD04TUBS4330-I69	LSHD04TUBS5430-I69
Lumen Output (lm)	3000	5760	7680	2800	5400	7200
Power (W)	20	36	48	20	36	48
Efficacy (lm/W)	160			150		
CRI	>80					
CCT	4000K			3000K		
Operating Temperature	- 20° to +40°C					
Lifetime	L80B10> 100 000h, at Ta=25°C					
Input Voltage	220-240 V					
Beam Angle	120°					
Ingress Protection	IP69K					
Impact Resistance	IK10					
Power Factor	>0.9					
Electrical Safety Class	Class I					
Compliance	CE/ RoHs					
Color Tolerance (MacAdam)	3 SDCM					
Weight (kg)	1.0	1.6	1.8	1.0	1.6	1.8
Product Dimension (mm)	600	1200	1500	600	1200	1500
Max luminaires in one loop	37	20	16	37	20	16
Control Interface	ON-OFF (standard) / DALI 2 (optional)					
Accessories & options	 Quick fit bracket  Anti-theft clamp  Anti-vibration bracket  Suspension kit (x2)					
Photometry						
Dimensions						
Remark	All values are given for Ta = 25oC and 4000K CCT with luminous flux & power output tolerance of +-5%					

Specifications are subject to change without notice.

Delta Electronics Europe

Zandsteen 15
2132 MZ Hoofddorp, The Netherlands
TEL: +31-20-655-0900
FAX: +31-20-655-0999

For more product information and sales inquiries,
please contact sleu@deltaww.com
www.delta-emea.com/ledlighting