

Linear LED Lighting

Altos Tubular Gen2

IP65 version

- IP65 and IK10 high protection level
- Modular design, easy replacement and maintenance
- Best flicker free light quality with very long lifetime
- High luminous efficacy of 160 lm/W
- Excellent visual comfort and uniformity of light thanks to a unique design
- Through-wiring for linking luminaires
- 5 years warranty

Applications



Industrial



Parking



Warehouse








 
Work Area



RoHS

www.deltaww-emea.com/ledlighting

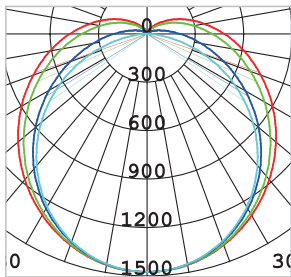

	LSHD04TUBS2240-I65	LSHD04TUBS4340-I65	LSHD04TUBS5440-I65	LSHD04TUBS2230-I65	LSHD04TUBS4330-I65	LSHD04TUBS5430-I65
Lumen Output (lm)	3000	5760	7680	2800	5200	7000
Power (W)	20	36	48	20	36	48
Efficacy (lm/W)	150	160		140	145	
CRI	>80					
CCT	4000K			3000K		
Operating Temperature	- 20° to +40°C					
Lifetime	L80B10> 100 000h, at Ta=25°C					
Input Voltage	220-240 V					
Beam Angle	120°					
Ingress Protection	IP65					
Impact Resistance	IK10					
Power Factor	>0.9					
Electrical Safety Class	Class I					
Compliance	CE/ RoHs					
Color Tolerance (MacAdam)	3 SDCM					
Weight (kg)	0.95	1.38	1.66	0.95	1.38	1.66
Product Length (mm)	600	1200	1500	600	1200	1500
Max luminaires in one loop	37	20	16	37	20	16
Control Interface	ON-OFF (standard) / DALI 2 (optional)					
Accessories & options	 Quick fit bracket  Anti-theft clamp  Anti-vibration bracket  Suspension kit (x2)					
Photometry						
Dimensions						
Remark	All values are given for Ta = 25°C and 4000K CCT with luminous flux & power output tolerance of +-5%					

Specifications are subject to change without notice.

Delta Electronics Netherlands B.V.

Zandsteen 15
2132 MZ Hoofddorp, The Netherlands
TEL: +31-20-655-0900
FAX: +31-20-655-0999

For more product information and sales inquiries, please contact
sleu@deltaww.com

www.delta-emea.com/ledlighting