



Tunetto

LED Lighting

- Excellent efficacy up to 161 lm/W (4000K) for retail store application
- Round shaped luminaire with acrylic reflectors
- Integrated designs of up lighting to achieve better illumination
- High uniformity and low glare optics
- Connected wireless IoT node control module (accessory)
- Reliable quality, manufacture capability, and global logistics by Delta Group

Applications



Retail



Warehouse



Work Area

www.delta-emea.com




	HFFBL534UD	HFFBL534CY
Lumen output (lm)	26500	26500
Input voltage (V)	120-277	347-480
Power (W)	165	165
Efficacy (lm/W)	161	161
CRI (Ra)	>83	
CCT (K)	4,000 K (Other CCT Available: 5,000K)	
Power factor	> 0.9	
Operating temp (°C)	Ta : -20~45+°C (Thermal foldback feature reduces lumen output for temperatures above Ta Max)	
Optics	90°	
Mounting	Hook	
Compliance	IEC 61000-3-2 Class C Harmonic (1-40)/ THD (Total Harmonic <20%)/ CE/ RoHs	
Control option	0-10V / IoT controller node	
Lifetime	>100,000 Hrs L70/B10 at Ta=25C; >55,000 Hrs L80B10 at Ta max	
Weight (kg)	6.8	


Remarks

Safety cable be mounted as default configuration.
 Up-lighting for retail store application.
 Junction box for wiring installation.

Photometry

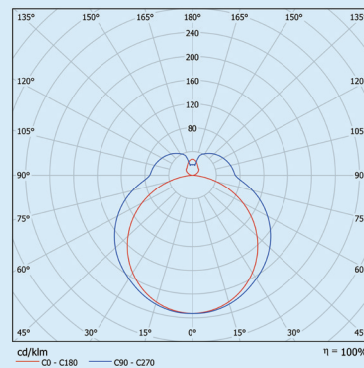

Dimensions (mm)
(Hook model)

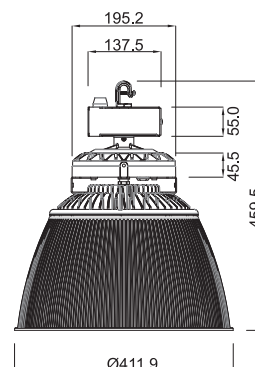

2022 ver.en-1.0

Delta Electronics (Netherlands) B.V.

Zandsteen 15, 2132 MZ Hoofddorp, The Netherlands

TEL : +31-20-655-0900

FAX : +31-20-655-0999

Email: sleu@deltaww.com

