

High-bay LED Lighting

Staccato Crane

Anti-vibration with built-in junction box

- A robust High-bay luminaire ideal for harsh environment
- Built-in junction box for easier electrical wiring
- Medium or narrow beam angle
- 0-10V (standard) and DALI (optional) dimming control
- 10kV surge protection
- Thermal control function to reduce the luminous flux for $T_a > T_{max}$
- Convenient installation with U-bracket and crossbar for increased vibration resistance
- 5 (+5) years warranty from Delta Electronics (project specific)

Applications




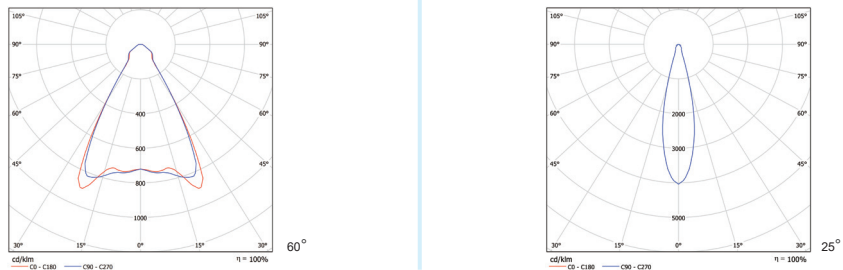
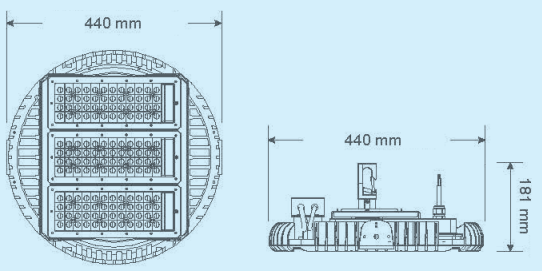
Crane



Industrial

www.deltaww-emea.com/ledlighting



	HBKBE460DE	HBKBE425DE
Lumen Output (lm)	18 900	19 000
Power (W)	135	150
Efficacy (lm/W)	140	127
CRI	>80	
CCT	4000K(Also available in 5000K)	
Operating Temperature	- 40° to +55°C	
Lifetime	L80/B10 >100 000 at Ta=25°;>70 000h at Ta=Max	L80/B10 >80 000 at Ta=25°;>45 000h at Ta=Max
Input Voltage	220-240 V	
Beam Angle	60°	25°
UGR	<25	<19
Ingress Protection	IP66	
Impact Resistance	IK10	
Power Factor	>0.9	
Electrical Safety Class	Class I	
Total Harmonic Distortion	<20%	
Color Tolerance (MacAdam)	3 SDCM	
Weight (kg)	9	
Product Dimension (Ø x H mm)	440 x 181	
Control Interface	DALI /10-0V	
Accessories & options	<p style="text-align: center;"> U-Bracket MA-01002A Crossbar MA-01009A </p> 	
Photometry		
Dimensions		
Remark	The lumen output and efficacy values are given for CCT 4000K	

Delta Electronics (Netherlands) B.V.

Zandsteen 15, 2132 MZ Hoofddorp, The Netherlands

E: sleu@deltaww.com

T: +31-20-655-0900