



Linear LED Lighting

Vega

Light-weight and efficient

- Compact and light-weight design with long lifetime
- High luminous efficacy up to 154 lm/W
- Convenient installation with easy-click fixation and press-fit electrical block
- Flicker-free light quality
- 5 years warranty

Applications



Parking



 


Warehouse



Cold Storage

www.deltaww-emea.com/ledlighting

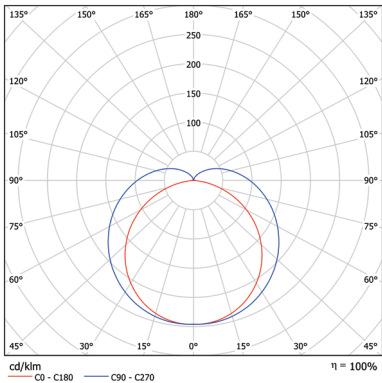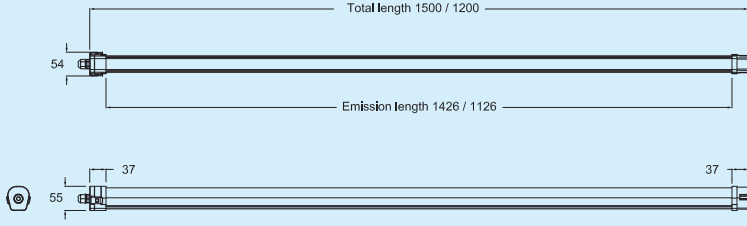

	BA-EL540ILG1N	BA-EL540NLG1N	BA-EL426ILG1N	BA-EL426NLG1N
Lumen Output (lm)	6 000		4 000	
Power (W)	40		26	
Efficacy (lm/W)	150		154	
CRI	>80			
CCT	4000K	5000K	4000K	5000K
Operating Temperature	- 30° to +40°C			
Lifetime	L80B10> 50 000h at Ta=25°C			
Input Voltage	220-240 V			
Beam Angle	H: 110° V: 150°			
UGR	H<25 V<29			
Ingress Protection	IP65			
Impact Resistance	IK08			
Power Factor	>0.9			
Electrical Safety Class	Class II			
Compliance	CE/ RoHs / ENEC			
Color Tolerance (MacAdam)	4 SDCM			
Weight (kg)	0.6		0.5	
Product Dimension (mm)	1 500		1 200	
Max luminaires in one loop	n.a			
Accessories & options	 MA -06V010STD Mounting clips 2 pcs per luminaire			
Photometry	 <p>Horizontal: 110° Vertical: 150°</p>			
Dimensions				

Delta Electronics (Netherlands) B.V.

Zandsteen 15, 2132 MZ Hoofddorp, The Netherlands

E: sleu@deltaww.com

T: +31-20-655-0900