




50" DLP LED Video Wall Cubes

Product Features

- Long-Lasting LED Light Engine
- Superior Color Uniformity
- Six-Axis Adjustment For Perfect Alignment
- Auto Color Calibration
- Advanced Optical & Screen Design
- Redundant Power Supply Module
- Wireless Diagnostics and Control
- Motorized 6-Axis Adjustment
- Auto Geometry Alignment For Quick Installation

www.deltadisplays.com



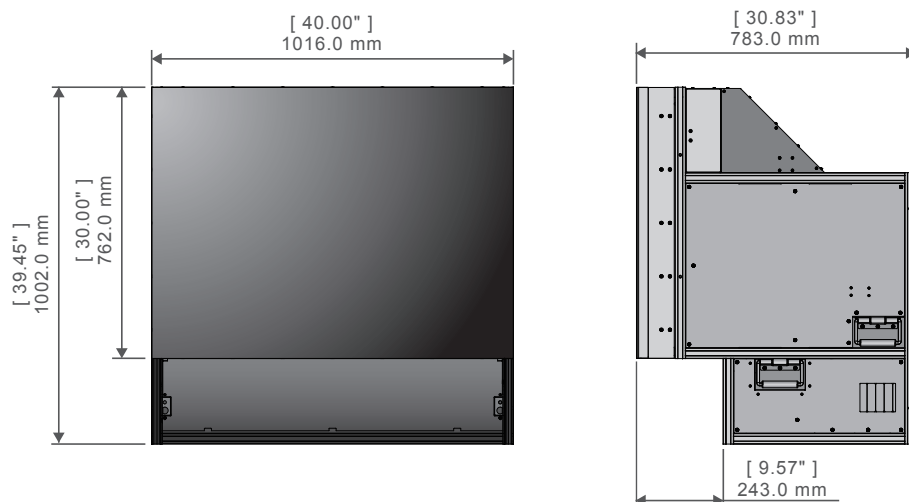

Specifications

Model	DVS-5070G9 / S9 FO CC				DVS-5050G9 / S9 DO CD		
Display Capabilities							
Native Resolution	SXGA+ , 1,400 x 1050				XGA , 1,024 x 768		
Display Technology	1-Chip DLP						
Brightness On Screen (Nits)	XPS Screen	Eco	478	XPS screen	Eco	422	
		Normal	563		Normal	534	
		Bright	668		Bright	591	
Dynamic Contrast	1,200,000 : 1						
White Point	3,200K , 6,500K , 7,500K and 9,300K						
Uniformity	> 96%						
System Adjustment - Optional	Auto Color Sensor Module						
	Motorized 6-Axis Adjustment						
Screen							
Screen Dimension (W X H)	1,015.0 x 761.0 mm						
Screen Type	XPS						
Screen Gap	< 0.1 mm						
Color Stability	Self Calibrating With Color Sensor						
Half Gain Angle (H / V)							
Horizontal	35°						
Vertical	27°						
Light Source							
Lamp Type	LED (RGB) , 6 x Redundancy for Each of 3 LED's						
Estimated Lamp Life	> 60,000 hrs , > 100,000 hrs (Eco)						
Operation							
Operating Temperature	5°C - 40°C (41°F - 104°F)						
Non-Operating Temperature	-20 °C - 60 °C (-4°F - 140°F)						
Humidity	10% - 90% , Non-Condensing						
Power Requirement							
Input Voltage	AC 90 - 240V @50/60Hz						
Consumption (Eco , Typ , Max)	150W , 225W , 270W						
Power Supply - Optional	Redundant Power Supply Module						
Mechanical							
Dimensions (W x H x D)	Front Access - 1,016.0 x 1,002.0 x 883.0 mm (40.0 x 39.5 x 34.8")						
	Rear Access - 1,016.0 x 1,002.0 x 783.0 mm (40.0 x 39.5 x 30.8")						
Weight	Front Access < 96 KG (212 lb) , Rear Access < 76 KG (168 lb)						
Interface							
Standard Inputs	Analog D-sub 15pin			Digital DVI-I			
	HDMI			Component Video BNC			
	CVBS BNC			5BNC (RGBHV or YPbPr)			
Optional Inputs	Display Port			3G-SDI			
	S-Video						
Standard Outputs	Digital DVI-D						
Input Frequency	24 – 62 Hz						
Signal Processing	Loop-Through (DVI , CVBS) Free Scaling						
Control							
Communication	RS-232 Port			RS-422 Port			
	IR Receiver			RJ-45 Ethernet			
IP Control Svstem - Optional	DVSWeb Control System Software						

*All specifications are subject to change without prior notice.

Ver: 03. 2014

Delta Group website :

www.deltaww.com

Product website :

www.deltadisplays.com

Contact E-mail :

VW.Sales@deltadisplays.com

Europe

FRANCE

Delta Electronics (France) S.A.
ZI du bois Chaland 2 15 rue des
Pyrénées, Lisses, 91056 Evry
Cedex, France

NETHERLANDS

Delta Electronics Europe
Zandsteen 15, 2132 MZ
Hoofddorp,
The Netherlands

SLOVAKIA

Delta Electronics (Slovakia) s.r.o.
Priemyselna ulica 4600/1
018 41 Dubnica nad Vahom,
Slovakia

North America

USA/ FREMONT

Delta Products Corporation
4405 Cushing Parkway,
Fremont, CA 94538, U.S.A.

USA/ PORTLAND

Delta Products Corporation
1600 NW Compton Drive,
Suite 100, Beaverton OR 97006,
U.S.A.

Asia

TAIWAN

Delta Electronics, Inc.
186 Ruey Kuang Road, Neihu,
Taipei 11491, Taiwan

KOREA

Delta Electronics (Korea) Inc.
234-9, Duck soo Building 7F,
Nonhyun-dong, Kangnam-Gu,
Seoul, Korea 135-010

JAPAN

Delta Electronics (Japan) Inc.
Delta Shibadaimon Building,
2-1-14 Shibadaimon, Minato-Ku,
Tokyo, 105-0012, Japan

THAILAND

Delta Electronics (Thailand) PCL.
909 Soi 9, E.P.Z., Bangpoo
Industrial Estate, Moo 4, Pattana
1 Rd., T.Prakasa, A.Muang
Samutprakarn 10280, Thailand

INDIA

Delta India Electronics Pvt. Ltd.
Plot No 43, Sector 35, HSIDC,
Gurgaon 122001, Haryana,
India

CHINA

Delta Electronics (Jiang Su) Ltd.
1688 Jiangxing East Road,
Wujiang
Economic Development Zone,
Wujiang City, Jiang Su
Province, China

SINGAPORE

Delta Electronics (Singapore)
1, Kaki Bukit Road 1, #03 -29,
Enterprise One, Singapore
415934

