




67" DLP LED Video Wall Cubes

Product Features

- Long-Lasting LED Light Engine
- Superior Color Uniformity
- Six-Axis Adjustment For Perfect Alignment
- Auto Color Calibration
- Advanced Optical & Screen Design
- Redundant Power Supply Module
- Wireless Diagnostics and Control
- Motorized 6-Axis Adjustment
- Auto Geometry Alignment For Quick Installation

www.deltadisplays.com



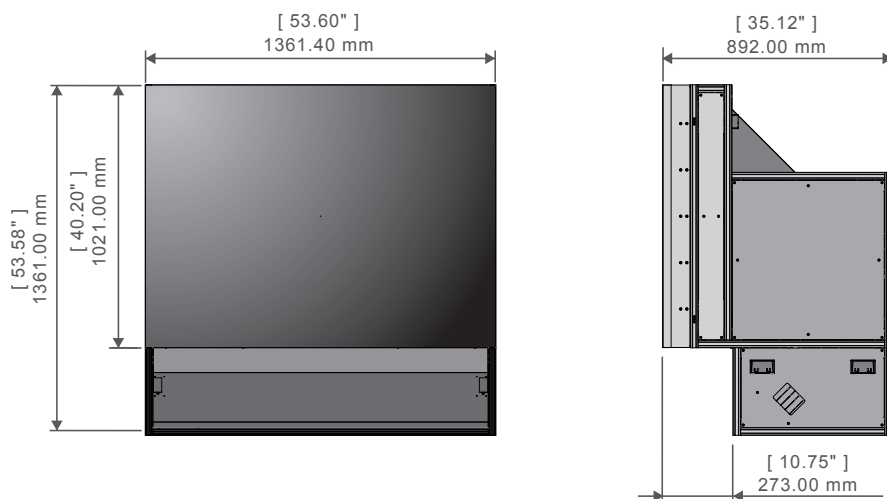

Specifications

Model	DVS-6770G9 / S9 FO CC				DVS-6750G9 / S9 DO CD			
Display Capabilities								
Native Resolution	SXGA+ , 1,400 x 1,050				XGA, 1,024 x 768			
Display Technology	1-Chip DLP							
Brightness On Screen (Nits)	XPS Screen	Eco	266	XPS Screen	Eco	235		
		Normal	313		Normal	298		
		Bright	372		Bright	329		
Dynamic Contrast	1,200,000 : 1							
White Point	3,200K , 6,500K , 7,500K and 9,300K							
Uniformity	> 96%							
System Adjustment - Optional	Auto Color Sensor Module							
	Motorized 6-Axis Adjustment							
Screen								
Screen Dimension (W X H)	1,359.9 x 1,019.6 mm							
Screen Type	XPS							
Screen Gap	< 0.1 mm							
Color Stability	Self Calibrating With Color Sensor							
Half Gain Angle (H / V)								
Horizontal	35°							
Vertical	27°							
Light Source								
Lamp Type	LED (RGB) , 6 x Redundancy For Each Of 3 LED's							
Estimated Lamp Life	> 60,000 hrs , > 100,000 hrs (Eco)							
Operation								
Operating Temperature	5°C - 40°C (41°F - 104°F)							
Non-Operating Temperature	-20 °C - 60 °C (-4°F - 140°F)							
Humidity	10% - 90% , Non-Condensing							
Power Requirement								
Input Voltage	AC 90 - 240V @50/60Hz							
Consumption (Eco , Typ , Max)	150W , 225W , 270W							
Power Supply - Optional	Redundant Power Supply Module							
Mechanical								
Dimensions (W x H x D)	Front Access - 1,361.4 x 1,361.0 x 992.0 mm (53.6 x 53.6 x 39.1")							
	Rear Access - 1,361.4 x 1,361.0 x 892.0 mm (53.6 x 53.6 x 35.1")							
Weight	Front Access < 100 KG (220 lb) , Rear Access < 80 KG (176 lb)							
Interface								
Standard Inputs	Analog D-Sub 15pin				Digital DVI-I			
	HDMI				Component Video BNC			
	CVBS BNC				5BNC (RGBHV or YPbPr)			
Optional Inputs	Display Port				3G-SDI			
	S-Video							
Standard Outputs	Digital DVI-D							
Input Frequency	24 – 62 Hz							
Signal Processing	Loop-Through (DVI, CVBS) Free Scaling							
Control								
Communication	RS-232 Port				RS-422 Port			
	IR Receiver				RJ-45 Ethernet			
IP Control Svstem - Optional	DVSWeb Control Svstem Software							

*All specifications are subject to change without prior notice.

Ver: 03. 2014

Delta Group website :

www.deltaww.com

Product website :

www.deltadisplays.com

Contact E-mail :

VW.Sales@deltadisplays.com

Europe

FRANCE

Delta Electronics (France) S.A.
ZI du bois Chaland 2 15 rue des
Pyrénées, Lisses, 91056 Evry
Cedex, France

NETHERLANDS

Delta Electronics Europe
Zandsteen 15, 2132 MZ
Hoofddorp,
The Netherlands

SLOVAKIA

Delta Electronics (Slovakia) s.r.o.
Priemyselna ulica 4600/1
018 41 Dubnica nad Vahom,
Slovakia

North America

USA/ FREMONT

Delta Products Corporation
4405 Cushing Parkway,
Fremont, CA 94538, U.S.A.

USA/ PORTLAND

Delta Products Corporation
1600 NW Compton Drive,
Suite 100, Beaverton OR 97006,
U.S.A.

Asia

TAIWAN

Delta Electronics, Inc.
186 Ruey Kuang Road, Neihu,
Taipei 11491, Taiwan

KOREA

Delta Electronics (Korea) Inc.
234-9, Duck soo Building 7F,
Nonhyun-dong, Kangnam-Gu,
Seoul, Korea 135-010

JAPAN

Delta Electronics (Japan) Inc.
Delta Shibadaimon Building,
2-1-14 Shibadaimon, Minato-Ku,
Tokyo, 105-0012, Japan

THAILAND

Delta Electronics (Thailand) PCL.
909 Soi 9, E.P.Z., Bangpoo
Industrial Estate, Moo 4, Pattana
1 Rd., T.Prakasa, A.Muang
Samutprakarn 10280, Thailand

INDIA

Delta India Electronics Pvt. Ltd.
Plot No 43, Sector 35, HSIDC,
Gurgaon 122001, Haryana,
India

CHINA

Delta Electronics (Jiang Su) Ltd.
1688 Jiangxing East Road,
Wujiang
Economic Development Zone,
Wujiang City, Jiang Su
Province, China

SINGAPORE

Delta Electronics (Singapore)
1, Kaki Bukit Road 1, #03-29,
Enterprise One, Singapore
415934

