



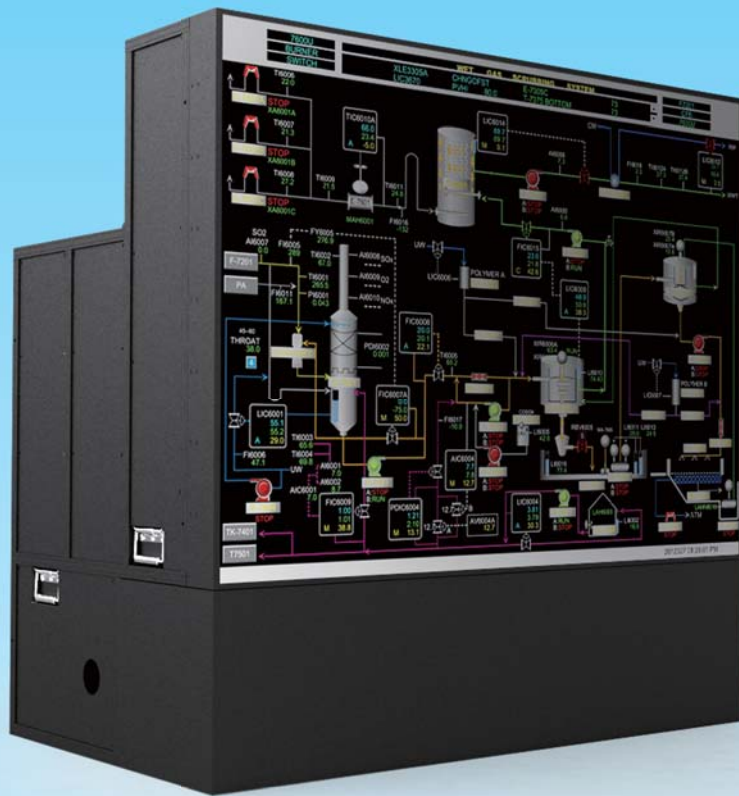

VR-80L ► DLP Video Wall

Product Features

- Long-lasting LED engine
- Superior color uniformity
- Six-axis adjustment for perfect alignment
- Advanced optical & screen design

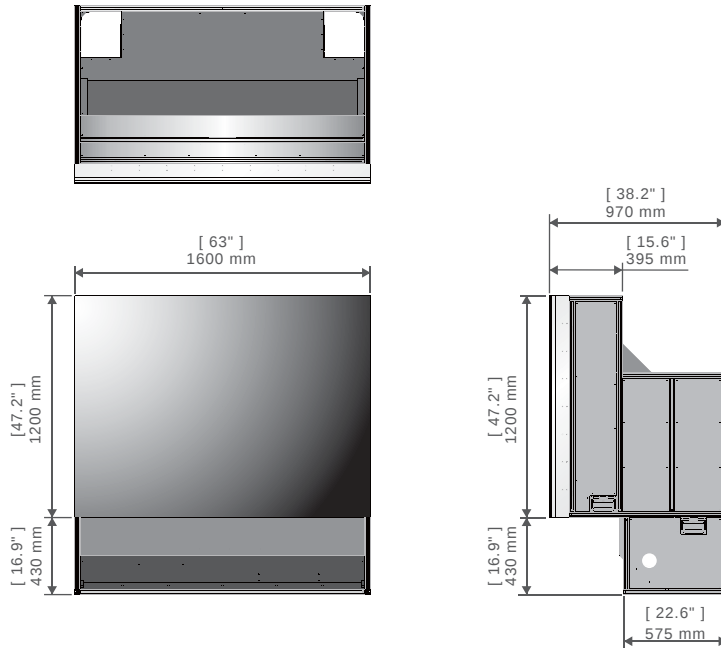

Specifications

Model	DVS-8078R8				DVS-8058R8	
Display Capabilities						
Native Resolution	SXGA+, 1400 X 1050			XGA, 1024 X 768		
Display Technology	1-chip DLP					
Brightness on screen (nits)	BB screen	Eco	88	BB screen	Eco	90
		Normal	112		Normal	96
		Bright	128		Bright	112
	XPS screen	Eco	88	XPS screen	Eco	172
		Normal	112		Normal	183
		Bright	128		Bright	214
Dynamic Contrast	1,500,000 : 1					
White Point	3200K, 6500K, 7500K and 9300K					
Uniformity	up to 96%					
Screen						
Screen Type	XPS, BB					
Screen Gap	< 1.0 mm Modular					
Color Stability	Self calibrating with color sensor					
Half Gain Angle (H/V)	XPS					
Horizontal	35°					
Vertical	27°					
Light Source						
Lamp Type	LED (RGB)					
Estimated Lamp Life	> 60,000 hrs, > 80,000 hrs (eco)					
Operation						
Operating Temperature	10°C - 40°C (50°F - 104°F)					
Non-operating Temperature	-20 °C - 60 °C (-4°F - 140°F)					
Humidity	10% - 90%, non-condensing					
Power Requirement						
AC Input Voltage	100- 240V+/-10%@50/60Hz					
Consumption (Eco, Typ, Max)	230W, 280W, 350W					
Mechanical						
Dimensions (W x H x D)	1600 x 1630 x 970 mm 63 x 64.2 x 38.2"					
Weight	< 170 KG					
Interface						
Standard Inputs	Analog D-sub 15pin		Digital DVI-I			
	Digital DVI-D		Component Video BNC			
	CVBS BNC		5BNC (RGBHV or YPbPr)			
Standard Outputs	Digital DVI-D		CVBS BNC			
Input Frequency	24 – 62 Hz					
Signal Processing	Loop-through (DVI, CVBS) free scaling					
Control						
Communication	RS-232 port		RS 422 port			
	IR Receiver					

*All specifications are subject to change without prior notice.

Delta Group website :
www.deltaww.com

Product website :
www.deltadisplays.com

Contact E-mail :
VW.Sales@deltadisplays.com

Europe

FRANCE

Delta Electronics (France) S.A.
ZI du bois Chaland 2 15 rue des
Pyrénées, Lisses, 91056 Evry
Cedex, France

NETHERLANDS

Delta Electronics Europe
Zandsteen 15, 2132 MZ
Hoofddorp,
The Netherlands

SLOVAKIA

Delta Electronics (Slovakia) s.r.o.
Priemyselna ulica 4600/1
018 41 Dubnica nad Vahom,
Slovakia

North America

USA / FREMONT

Delta Products Corporation
4405 Cushing Parkway,
Fremont, CA 94538, U.S.A.

USA / PORTLAND

1600 NW Compton Drive,
Suite 100, Beaverton OR 97006,
U.S.A.

Asia

TAIWAN

Delta Electronics, Inc.
186 Ruey Kuang Road, Neihu,
Taipei 11491, Taiwan

KOREA

Delta Electronics (Korea) Inc.
234-9, Duck soo Building 7F,
Nonhyun-dong, Kangnam-Gu,
Seoul, Korea 135-010

JAPAN

Delta Electronics (Japan) Inc.
Delta Shibadaimon Building,
2-1-14 Shibadaimon, Minato-Ku,
Tokyo, 105-0012, Japan

THAILAND

Delta Electronics (Thailand) PCL.
909 Soi 9, E.P.Z., Bangpoo
Industrial Estate, Moo 4, Pattana
1 Rd., T.Prakasa, A.Muang
Samutprakarn 10280, Thailand

INDIA

Delta India Electronics Pvt. Ltd.
Plot No 43, Sector 35, HSIDC,
Gurgaon 122001, Haryana,
India

CHINA

Delta Electronics (Jiang Su) Ltd.
1688 Jiangxing East Road,
Wujiang
Economic Development Zone,
Wujiang City, Jiang Su
Province, China

SINGAPORE

Delta Electronics (Singapore)
1, Kaki Bukit Road 1, #03 -29,
Enterprise One, Singapore
415934